

5/3-way solenoid valve, G1/8 - Series 3

Product code: 368-011-02-U77

Datasheet creation date: 10/03/2025 11:01

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------------|----------------------|
| Mod. | 368-011-02 |
| Function | 5/3CC |
| Flow rate (Nl/min) | 700 |
| Operating pressure | 2 ÷ 10 |
| Pilot pressure | - |
| Manual override | = bistabile standard |
| Dimensions of the solenoid | U7 = PET / 22 x 22 |
| Solenoid voltage | 7 = 24 V DC |

5/3-way solenoid valve, G1/8 - Series 3

Product code: 368-011-02-U77

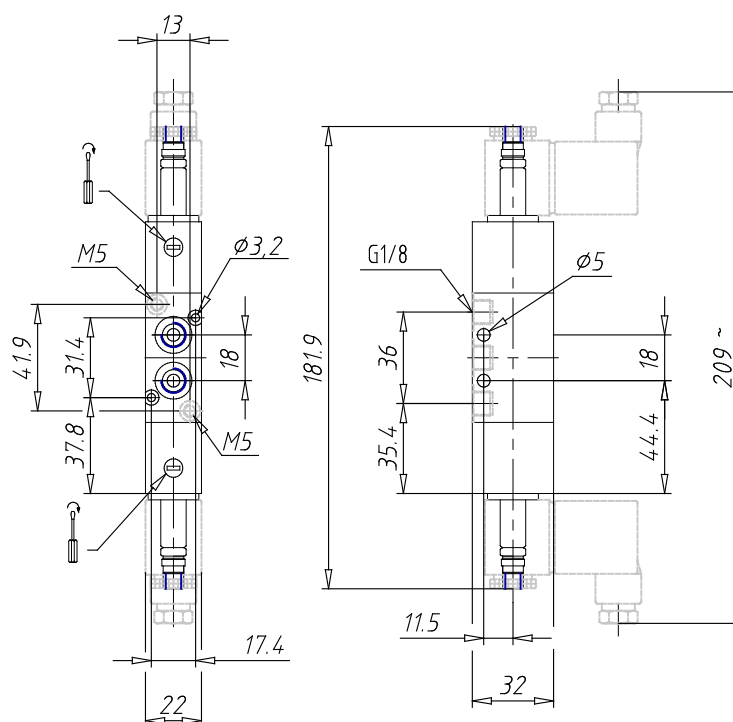

DIMENSIONS

| | |
|-----------------------------------|----------------------|
| Mod. | 368-011-02 |
| Function | 5/3CC |
| Flow rate (NI/min) | 700 |
| Operating pressure | 2 ÷ 10 |
| Pilot pressure | - |
| Manual override | = bistabile standard |
| Dimensions of the solenoid | U7 = PET / 22 x 22 |
| Solenoid voltage | 7 = 24 V DC |