


3/2-way solenoid valve, G1/4, bistable - Mod. 434-011... - Serie 4

Product code: 434-011-22IL

Datasheet creation date: 10/03/2025 11:58

Check the most updated document online [click here](#)

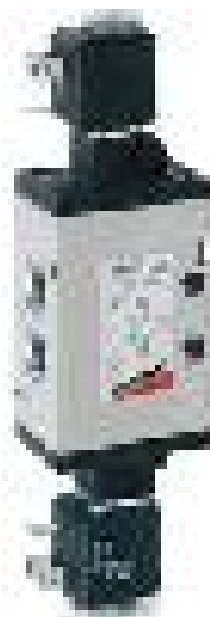


TECHNICAL DATA

Mod.	434-011-22
Mounting	
Function	3/2
Flow rate (NI/min)	1250
Operating pressure	2.5 ÷ 10
Pilot pressure	
Type of manual override	IL = bistable, lever type (available on demand)
Dimensions of the solenoid	No solenoid
Solenoid voltage	

3/2-way solenoid valve, G1/4, bistable - Mod. 434-011... - Serie 4

Product code: 434-011-22IL

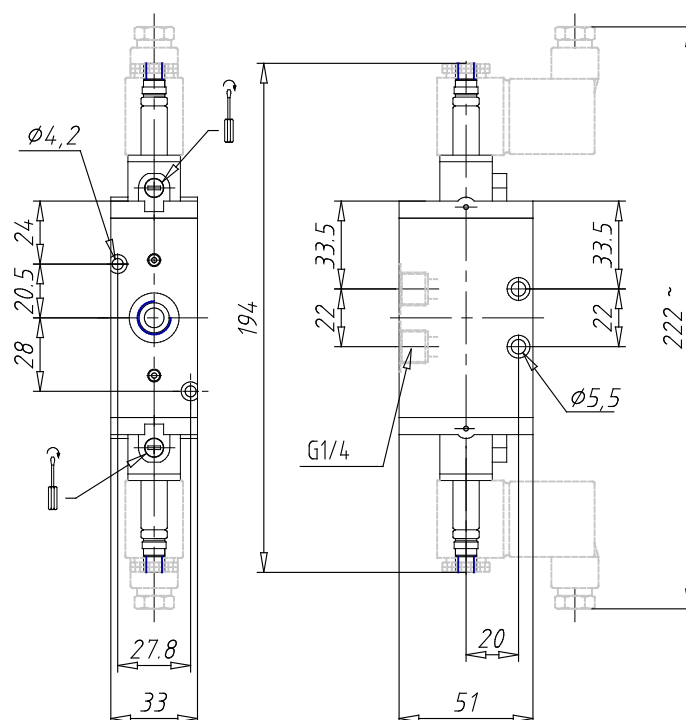

DIMENSIONS

Mod.	434-011-22
Mounting	
Function	3/2
Flow rate (NI/min)	1250
Operating pressure	2.5 ÷ 10
Pilot pressure	
Type of manual override	IL = bistable, lever type (available on demand)
Dimensions of the solenoid	No solenoid
Solenoid voltage	