

3/2-way solenoid valve G1/8, monostable - Serie 4

Product code: 438-015-22-A83

Datasheet creation date: 10/03/2025 12:00

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	438-015-22
Function	3/2 NC
Flow rate (NI/min)	650
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A8 = PPS / 30 x 30
Solenoid voltage	3 = 24V DC

3/2-way solenoid valve G1/8, monostable - Serie 4

Product code: 438-015-22-A83

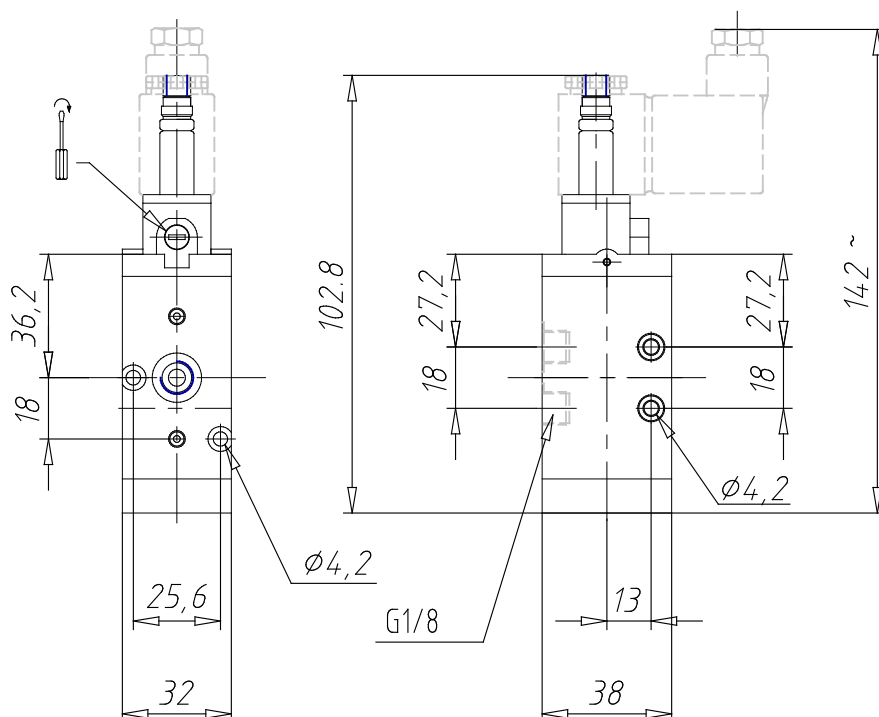

DIMENSIONS

Mod.	438-015-22
Function	3/2 NC
Flow rate (NI/min)	650
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A8 = PPS / 30 x 30
Solenoid voltage	3 = 24V DC