

5/2-way solenoid valve, G1/2, bistable - Series 4

Product code: 452C-011-50-A6B

Datasheet creation date: 10/03/2025 11:50

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	452C-011-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2 ÷ 10
Type of manual override	= bistabile standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	B = 24 V 50/60 Hz - 12 VA

5/2-way solenoid valve, G1/2, bistable - Series 4

Product code: 452C-011-50-A6B

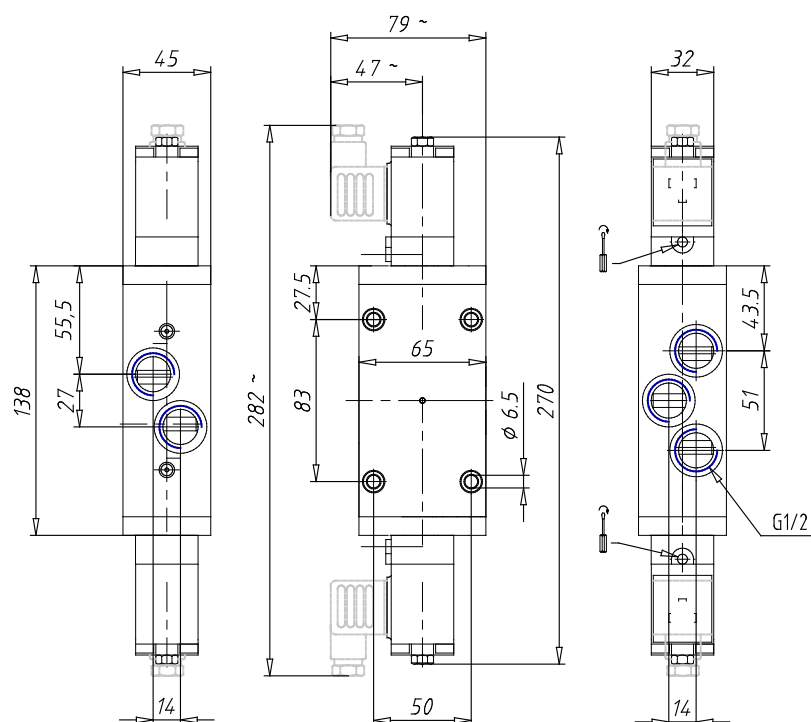

DIMENSIONS

Mod.	452C-011-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2 ÷ 10
Type of manual override	= bistabile standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	B = 24 V 50/60 Hz - 12 VA