

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-015-50-A63

Datasheet creation date: 10/03/2025 11:50

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	452C-015-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	3 = 24 V DC - 10 W

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-015-50-A63

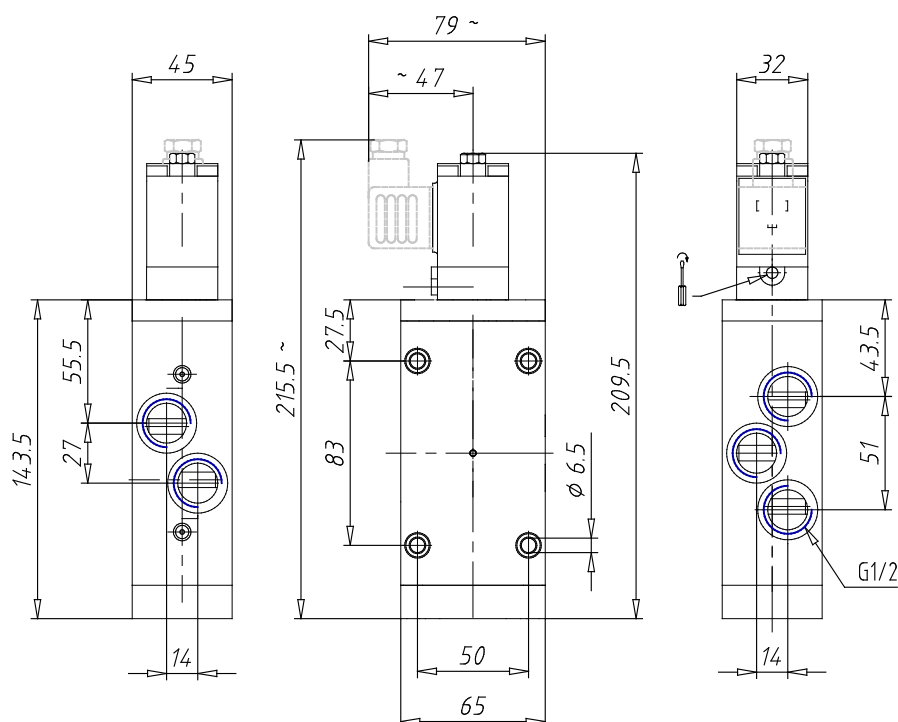

DIMENSIONS

Mod.	452C-015-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	3 = 24 V DC - 10 W