

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-015-50-A6D

Datasheet creation date: 10/03/2025 11:50

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------------|----------------------------|
| Mod. | 452C-015-50 |
| Function | 5/2 |
| Flow rate (NI/min) | 2500 |
| Operating pressure | 2.5 ÷ 10 |
| Type of manual override | = bistable, standard |
| Dimensions of the solenoid | A6 = 32x32 |
| Solenoid voltage | D = 110 V 50/60 Hz - 12 VA |

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-015-50-A6D

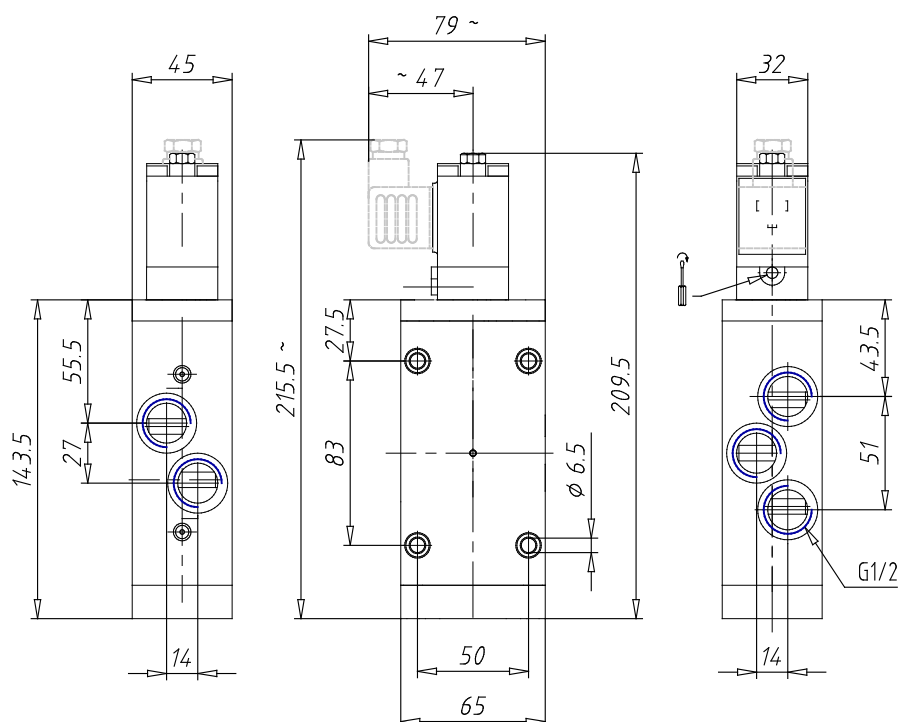

DIMENSIONS

| | |
|-----------------------------------|----------------------------|
| Mod. | 452C-015-50 |
| Function | 5/2 |
| Flow rate (NI/min) | 2500 |
| Operating pressure | 2.5 ÷ 10 |
| Type of manual override | = bistable, standard |
| Dimensions of the solenoid | A6 = 32x32 |
| Solenoid voltage | D = 110 V 50/60 Hz - 12 VA |