

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-016-50-A6E

Datasheet creation date: 10/03/2025 11:50

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	452C-016-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	E = 230 V 50/60 Hz - 12 VA

5/2-way solenoid valve, G1/2, monostable - Series 4

Product code: 452C-016-50-A6E

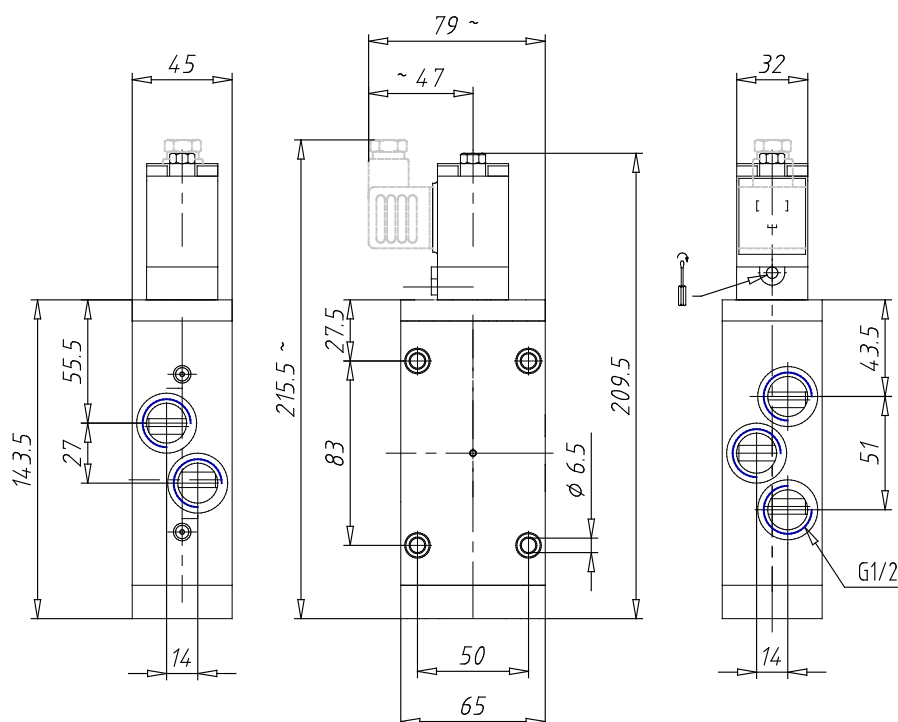

DIMENSIONS

Mod.	452C-016-50
Function	5/2
Flow rate (NI/min)	2500
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	A6 = 32x32
Solenoid voltage	E = 230 V 50/60 Hz - 12 VA