

5/2-way solenoid valve, G1/4, bistable - Series 4

Product code: 454-011-22-U7H

Datasheet creation date: 10/03/2025 11:59

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	454-011-22
Function	5/2
Flow rate (NI/min)	1250
Operating pressure	2 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	H = 12 V DC

5/2-way solenoid valve, G1/4, bistable - Series 4

Product code: 454-011-22-U7H

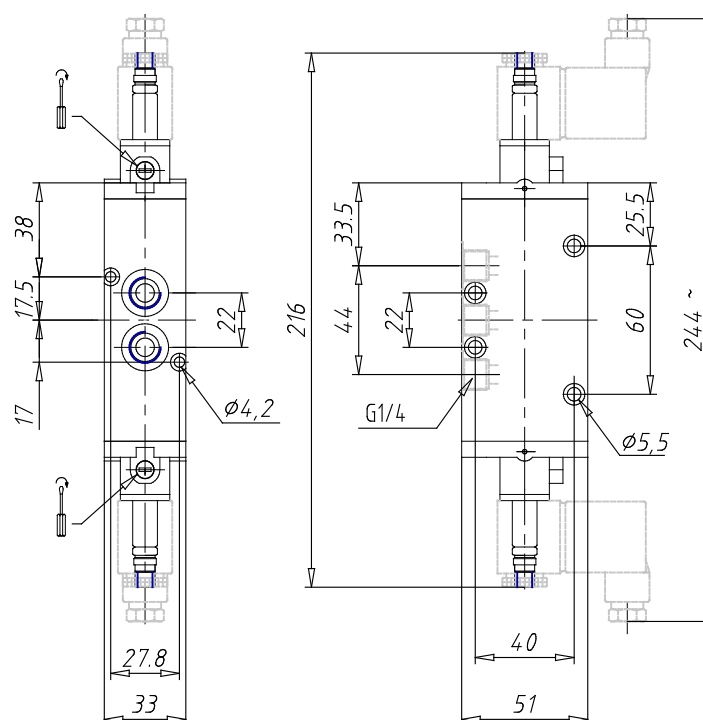

DIMENSIONS

Mod.	454-011-22
Function	5/2
Flow rate (NI/min)	1250
Operating pressure	2 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	H = 12 V DC