

- 5/2-way solenoid valves, G1/8, bistable

Product code: 458-011-22-U77

Datasheet creation date: 10/03/2025 12:00

Check the most updated document online [click here](#)




■ TECHNICAL DATA

Mod.	458-011-22
Function	5/2
Flow rate (NI/min)	650
Operating pressure	2 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	7 = 24 V DC

- 5/2-way solenoid valves, G1/8, bistable

Product code: 458-011-22-U77

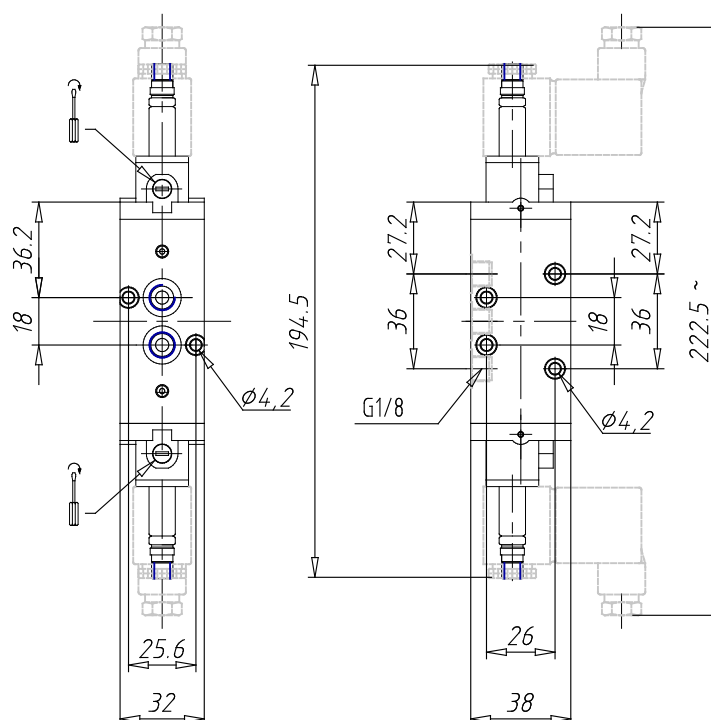

DIMENSIONS

Mod.	458-011-22
Function	5/2
Flow rate (NI/min)	650
Operating pressure	2 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	7 = 24 V DC