

5/2-way solenoid valves, G1/8, monostable - Series 4

Product code: 458-015-22-U7J

Datasheet creation date: 10/03/2025 12:01

Check the most updated document online [click here](#)




TECHNICAL DATA

Mod.	458-015-22
Function	5/2
Flow rate (NI/min)	650
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	J = 230V - 50/60Hz

5/2-way solenoid valves, G1/8, monostable - Series 4

Product code: 458-015-22-U7J

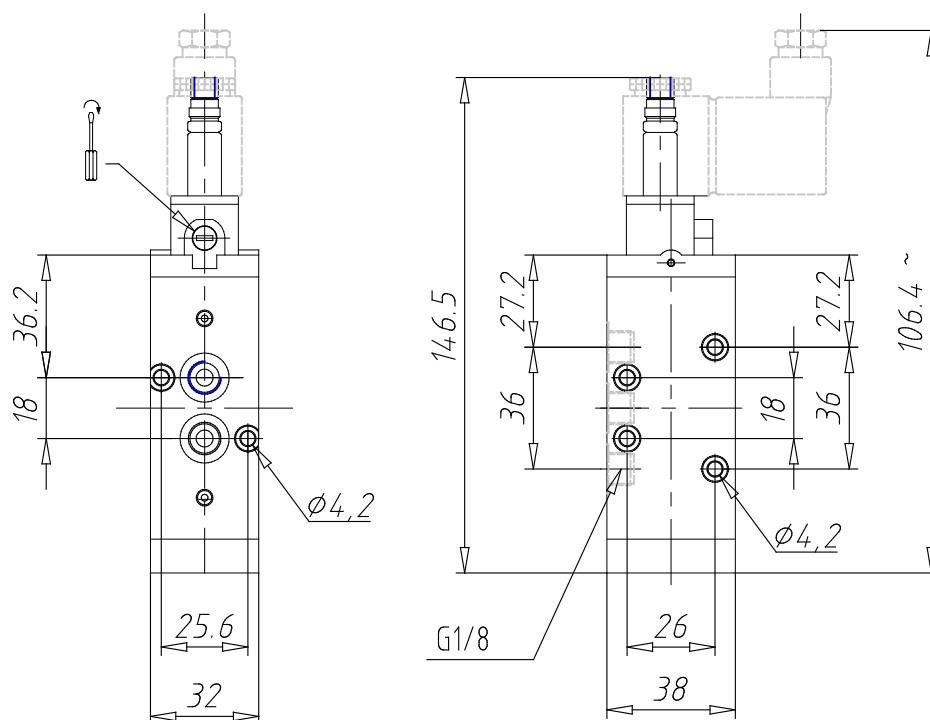

DIMENSIONS

Mod.	458-015-22
Function	5/2
Flow rate (NI/min)	650
Operating pressure	2.5 ÷ 10
Type of manual override	= bistable, standard
Dimensions of the solenoid	U7 = PET / 22 x 22
Solenoid voltage	J = 230V - 50/60Hz