

## Anti-rotation guide units - Series 45

Product code: 45NHT040A0425

Datasheet creation date: 10/03/2025 02:09

Check the most updated document online [click here](#)




### TECHNICAL DATA

|                      |  |
|----------------------|--|
| <b>Series</b>        | 45   |
| <b>Diameter (mm)</b> | 40   |
| <b>Version</b>       | N = standard   |
| <b>Operation</b>     | HT = "H" self lubricating guide                                |
| <b>Materials</b>     | A = anodized aluminium body, stainless steel columns AISI 420B |
| <b>Stroke (mm)</b>   | 425  |

## Anti-rotation guide units - Series 45

Product code: 45NHT040A0425

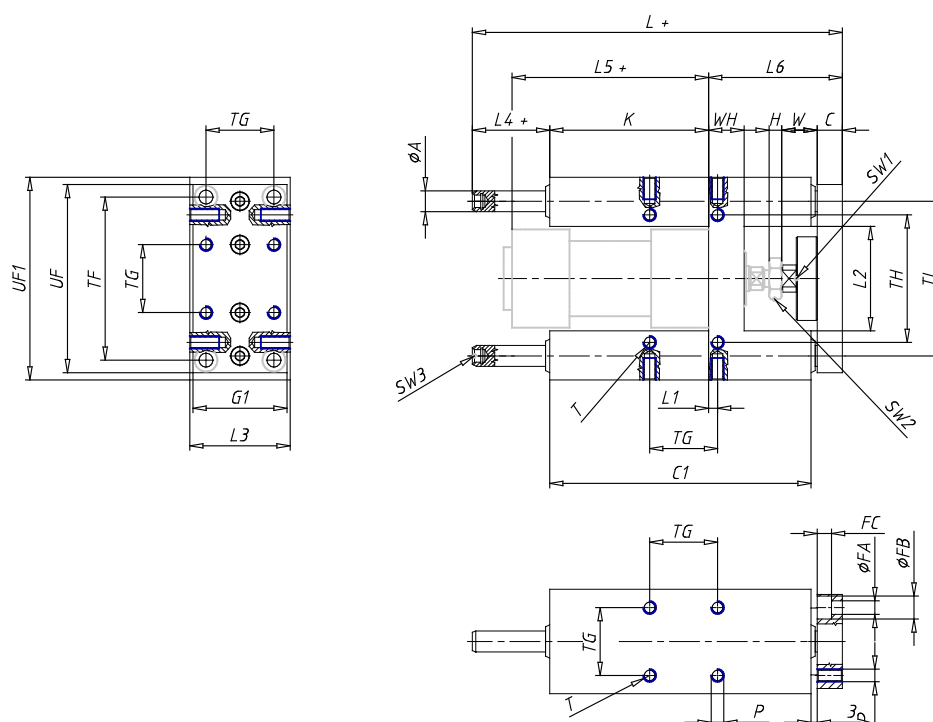

### DIMENSIONS

|          |       |
|----------|-------|
| TF (mm)  | 84    |
| TG (mm)  | 38.0  |
| TH (mm)  | 69.0  |
| TI (mm)  | 87    |
| TL (mm)  | 0.0   |
| UF1 (mm) | 115   |
| UF (mm)  | 110   |
| G1 (mm)  | 54    |
| A (mm)   | 16    |
| WH (mm)  | 21    |
| C1 (mm)  | 140   |
| H (mm)   | 7     |
| W (mm)   | 22    |
| C (mm)   | 12    |
| L (mm)   | 192.0 |
| L1 (mm)  | 11    |
| L2 (mm)  | 58.2  |
| L3 (mm)  | 58    |
| L4 (mm)  | 37    |
| L5 (mm)  | 105.0 |
| P        | M6    |
| FB (mm)  | 11.0  |
| SW1 (mm) | 15    |

|          |    |
|----------|----|
| SW2 (mm) | 19 |
| SW3 (mm) | 6  |