

## Anti-rotation guide units - Series 45

Product code: 45NHT040A1200

Datasheet creation date: 10/03/2025 02:10

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	45
<b>Diameter (mm)</b>	40
<b>Version</b>	N = standard
<b>Operation</b>	HT = "H" self lubricating guide
<b>Materials</b>	A = anodized aluminium body, stainless steel columns AISI 420B
<b>Stroke (mm)</b>	1200

## Anti-rotation guide units - Series 45

Product code: 45NHT040A1200

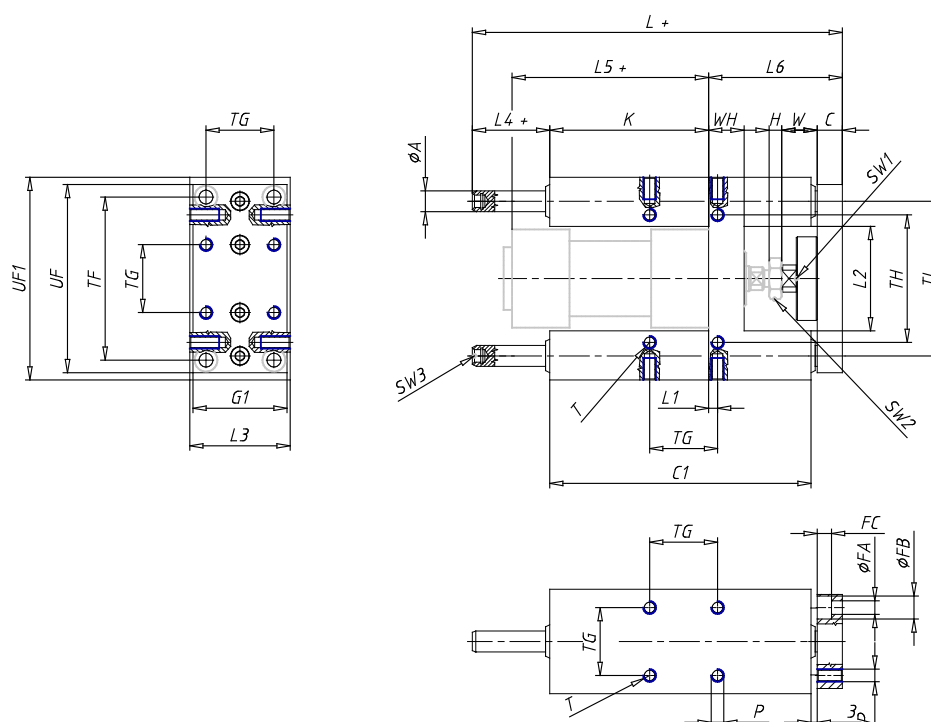

### DIMENSIONS

TF (mm)	84
TG (mm)	38.0
TH (mm)	69.0
TI (mm)	87
TM (mm)	0
TL (mm)	0.0
TN (mm)	0
UF1 (mm)	115
UF (mm)	110
G1 (mm)	54
A (mm)	16
WH (mm)	21
C1 (mm)	140
H (mm)	7
W (mm)	22
C (mm)	12
K (mm)	81
L (mm)	192.0
L1 (mm)	11
L2 (mm)	58.2
L3 (mm)	58
L4 (mm)	37
L5 (mm)	105.0

L6 (mm)	74.0
L7 (mm)	0.0
L8 (mm)	0
P	M6
P1	-
T (mm)	14
EA (mm)	0.0
EB (mm)	0
EC (mm)	0.0
FA (mm)	6.5
FB (mm)	11.0
FC (mm)	6.8
SW1 (mm)	15
SW2 (mm)	19
SW3 (mm)	6