

## Anti-rotation guide units - Series 45

Product code: 45NHT050A1100

Datasheet creation date: 10/03/2025 02:12

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	45
<b>Diameter (mm)</b>	50
<b>Version</b>	N = standard
<b>Operation</b>	HT = "H" self lubricating guide
<b>Materials</b>	A = anodized aluminium body, stainless steel columns AISI 420B
<b>Stroke (mm)</b>	1100

## Anti-rotation guide units - Series 45

Product code: 45NHT050A1100

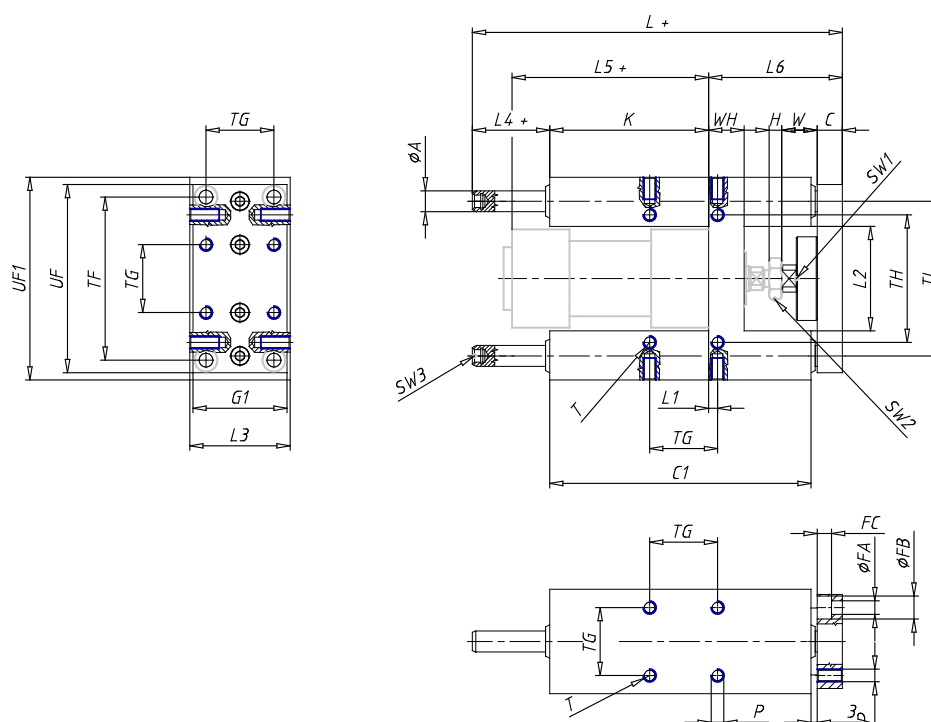

### DIMENSIONS

TF (mm)	100
TG (mm)	46.5
TH (mm)	85.0
TI (mm)	104
TM (mm)	0
TL (mm)	0.0
TN (mm)	0
UF1 (mm)	137
UF (mm)	130
G1 (mm)	63
A (mm)	20
WH (mm)	26
C1 (mm)	149
H (mm)	8
W (mm)	26
C (mm)	15
K (mm)	78
L (mm)	205.0
L1 (mm)	20
L2 (mm)	70.2
L3 (mm)	70
L4 (mm)	38
L5 (mm)	106.0

L6 (mm)	89.0
L7 (mm)	0.0
L8 (mm)	0
P	M8
P1	-
T (mm)	16
EA (mm)	0.0
EB (mm)	0
EC (mm)	0.0
FA (mm)	9.0
FB (mm)	15.0
FC (mm)	9.0
SW1 (mm)	22
SW2 (mm)	24
SW3 (mm)	6