

## Anti-rotation guide units - Series 45

Product code: 45NHT080A0400

Datasheet creation date: 10/03/2025 02:14

Check the most updated document online [click here](#)




### TECHNICAL DATA

|                      |  |
|----------------------|--|
| <b>Series</b>        | 45   |
| <b>Diameter (mm)</b> | 80   |
| <b>Version</b>       | N = standard   |
| <b>Operation</b>     | HT = "H" self lubricating guide                                |
| <b>Materials</b>     | A = anodized aluminium body, stainless steel columns AISI 420B |
| <b>Stroke (mm)</b>   | 400  |

## Anti-rotation guide units - Series 45

Product code: 45NHT080A0400

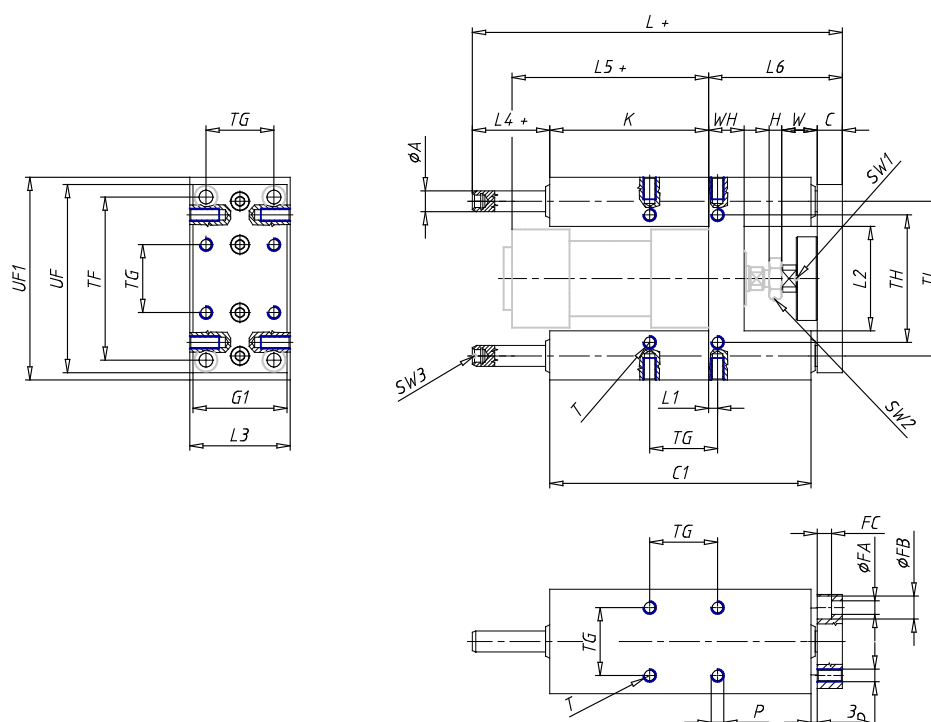

### DIMENSIONS

|          |       |
|----------|-------|
| TF (mm)  | 130   |
| TG (mm)  | 72.0  |
| TH (mm)  | 130.0 |
| TI (mm)  | 148   |
| TM (mm)  | 0     |
| TL (mm)  | 0.0   |
| TN (mm)  | 0     |
| UF1 (mm) | 189   |
| UF (mm)  | 180   |
| G1 (mm)  | 100   |
| A (mm)   | 25    |
| WH (mm)  | 34    |
| C1 (mm)  | 195   |
| H (mm)   | 9     |
| W (mm)   | 32    |
| C (mm)   | 20    |
| K (mm)   | 128   |
| L (mm)   | 280.0 |
| L1 (mm)  | 21    |
| L2 (mm)  | 105.4 |
| L3 (mm)  | 105   |
| L4 (mm)  | 42    |
| L5 (mm)  | 128.0 |

|          |       |
|----------|-------|
| L6 (mm)  | 110.0 |
| L7 (mm)  | 0.0   |
| L8 (mm)  | 0     |
| P        | M10   |
| P1       | -     |
| T (mm)   | 20    |
| EA (mm)  | 0.0   |
| EB (mm)  | 0     |
| EC (mm)  | 0.0   |
| FA (mm)  | 11.0  |
| FB (mm)  | 18.0  |
| FC (mm)  | 11.0  |
| SW1 (mm) | 27    |
| SW2 (mm) | 30    |
| SW3 (mm) | 6     |