

## Anti-rotation guide units - Series 45

Product code: 45NUT080A0160

Datasheet creation date: 10/03/2025 02:01

Check the most updated document online [click here](#)




### TECHNICAL DATA

|                      |  |
|----------------------|--|
| <b>Series</b>        | 45   |
| <b>Diameter (mm)</b> | 80   |
| <b>Version</b>       | N = standard   |
| <b>Operation</b>     | UT = "U" self lubricating guide                                |
| <b>Materials</b>     | A = anodized aluminium body, stainless steel columns AISI 420B |
| <b>Stroke (mm)</b>   | 160  |

## Anti-rotation guide units - Series 45

Product code: 45NUT080A0160

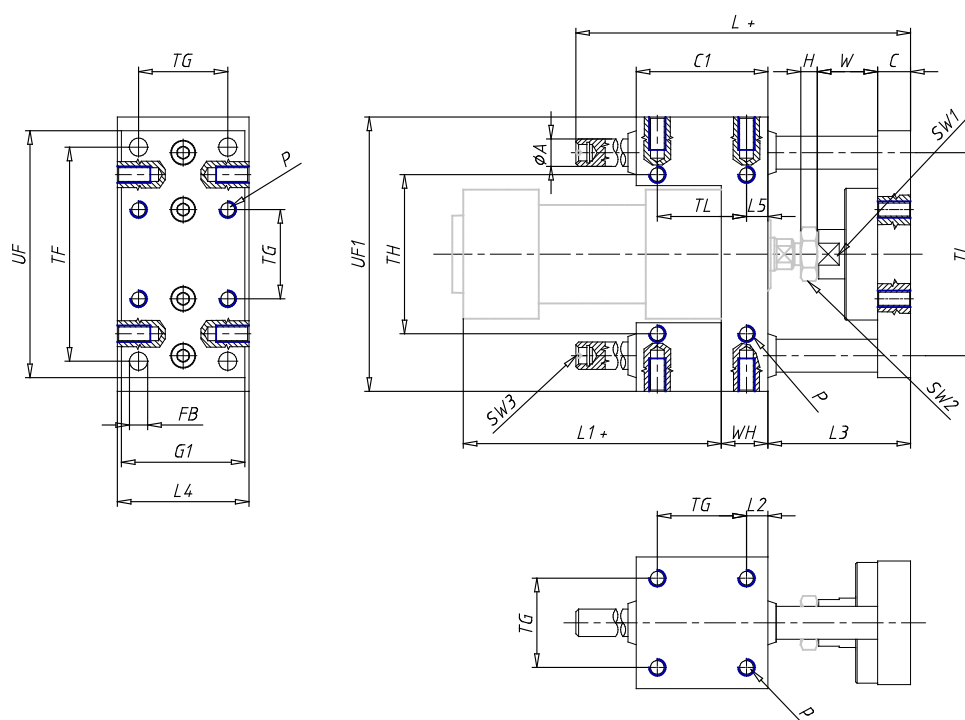

### DIMENSIONS

|          |       |
|----------|-------|
| TF (mm)  | 130   |
| TG (mm)  | 72.0  |
| TH (mm)  | 130.0 |
| TI (mm)  | 130   |
| TM (mm)  | 0     |
| TL (mm)  | 50.0  |
| TN (mm)  | 0     |
| UF1 (mm) | 165   |
| UF (mm)  | 155   |
| G1 (mm)  | 90    |
| A (mm)   | 20    |
| WH (mm)  | 34    |
| C1 (mm)  | 90    |
| H (mm)   | 9     |
| W (mm)   | 32    |
| C (mm)   | 16    |
| K (mm)   | 0     |
| L (mm)   | 170.0 |
| L1 (mm)  | 128   |
| L2 (mm)  | 9.0   |
| L3 (mm)  | 72    |
| L4 (mm)  | 98    |
| L5 (mm)  | 20.0  |

|          |      |
|----------|------|
| L6 (mm)  | 0.0  |
| L7 (mm)  | 0.0  |
| L8 (mm)  | 0    |
| P        | M10  |
| P1       | -    |
| T (mm)   | 0    |
| EA (mm)  | 0.0  |
| EB (mm)  | 0    |
| EC (mm)  | 0.0  |
| FA (mm)  | 0.0  |
| FB (mm)  | 11.0 |
| FC (mm)  | 0.0  |
| SW1 (mm) | 27   |
| SW2 (mm) | 30   |
| SW3 (mm) | 6    |