

## 5/2-way solenoid valve, G1/2 - Series 4

Product code: 462N-011-22-G77

Datasheet creation date: 10/03/2025 11:51

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Mod.</b>	462N-011-22
<b>Function</b>	5/3 CC
<b>Flow rate (NI/min)</b>	3300
<b>Operating pressure</b>	2.5 ÷ 10
<b>Pilot pressure</b>	-
<b>Type of manual override</b>	= bistable, standard
<b>Dimensions of the solenoid</b>	G7 = PA 6 V0 30 x 30
<b>Solenoid voltage</b>	7 = 24 V DC

## 5/2-way solenoid valve, G1/2 - Series 4

Product code: 462N-011-22-G77

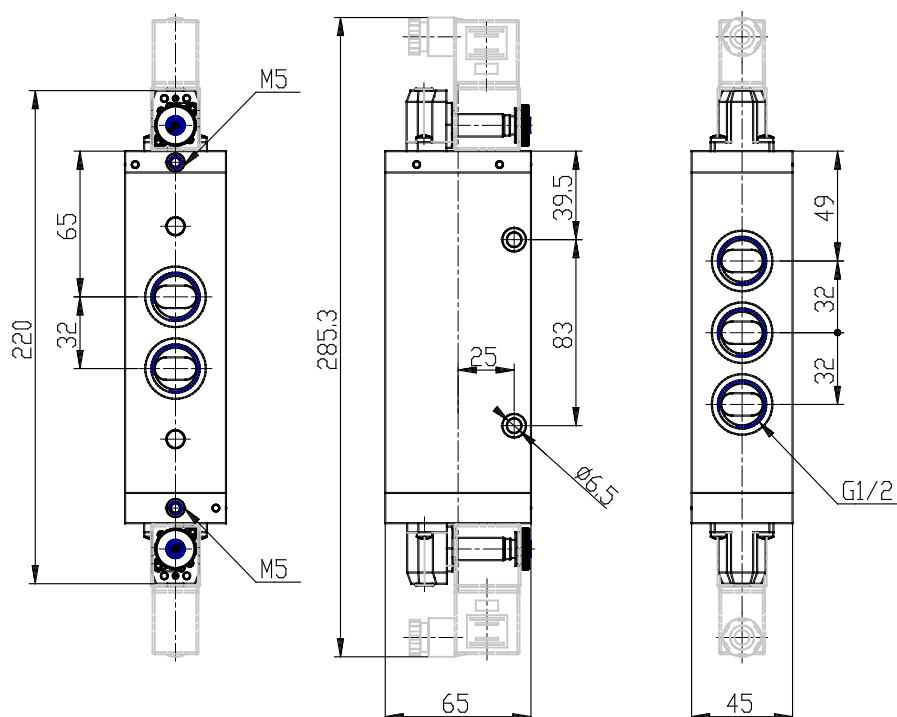

### DIMENSIONS

<b>Mod.</b>	462N-011-22
<b>Function</b>	5/3 CC
<b>Flow rate (NI/min)</b>	3300
<b>Operating pressure</b>	2.5 ÷ 10
<b>Pilot pressure</b>	-
<b>Type of manual override</b>	= bistable, standard
<b>Dimensions of the solenoid</b>	G7 = PA 6 V0 30 x 30
<b>Solenoid voltage</b>	7 = 24 V DC