


5/3-way solenoid valve, G1/8 - Series 4

Product code: 468-011-22-U77

Datasheet creation date: 10/03/2025 12:01

Check the most updated document online [click here](#)

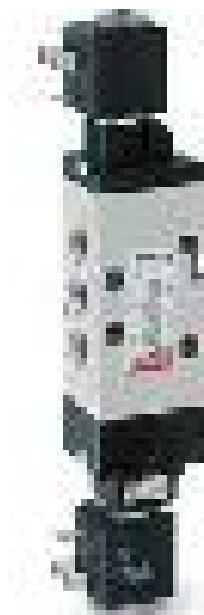


TECHNICAL DATA

| | |
|-----------------------------------|----------------------|
| Mod. | 468-011-22 |
| Function | 5/3 CC |
| Flow rate (NI/min) | 600 |
| Operating pressure | 2.5 ÷ 10 |
| Type of manual override | = bistable, standard |
| Dimensions of the solenoid | U7 = PET / 22 x 22 |
| Solenoid voltage | 7 = 24 V DC |

5/3-way solenoid valve, G1/8 - Series 4

Product code: 468-011-22-U77

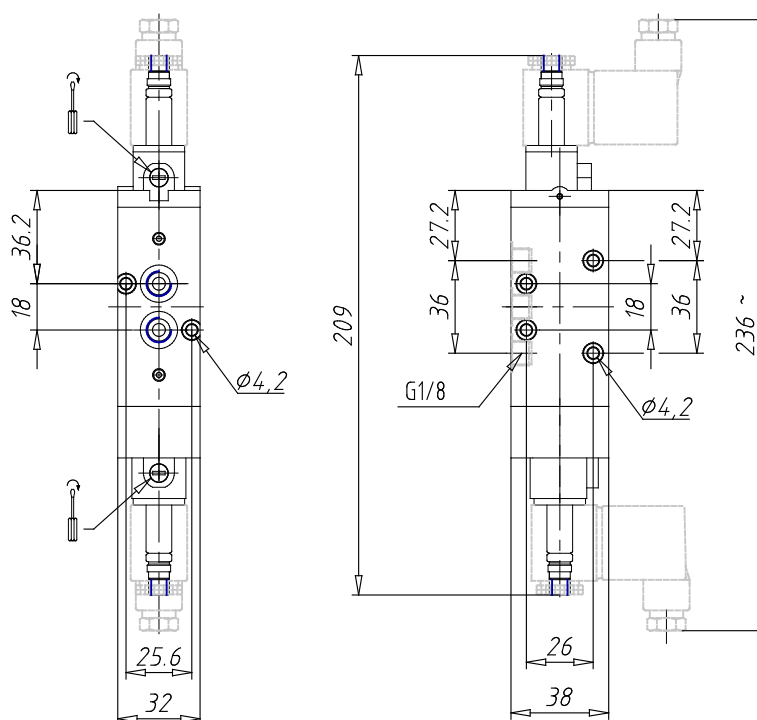

DIMENSIONS

| | |
|-----------------------------------|----------------------|
| Mod. | 468-011-22 |
| Function | 5/3 CC |
| Flow rate (NI/min) | 600 |
| Operating pressure | 2.5 ÷ 10 |
| Type of manual override | = bistable, standard |
| Dimensions of the solenoid | U7 = PET / 22 x 22 |
| Solenoid voltage | 7 = 24 V DC |