

Rodless cylinders - Series 52

Product code: 52G2P50A0630

Datasheet creation date: 08/03/2025 13:57

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------|-----------------------------------------------------------------------------|
| Series | 52G2P50A |
| Diameter (mm) | 50 |
| Version | G = with slide bearing |
| Operation | 2 = double-acting, cushioned |
| Materials | P = anodized AL profile tube, NBR and Polyurethane seals, standard carriage |
| Construction | A = standard |
| Stroke Cylinder (mm) | 630 |

Rodless cylinders - Series 52

Product code: 52G2P50A0630

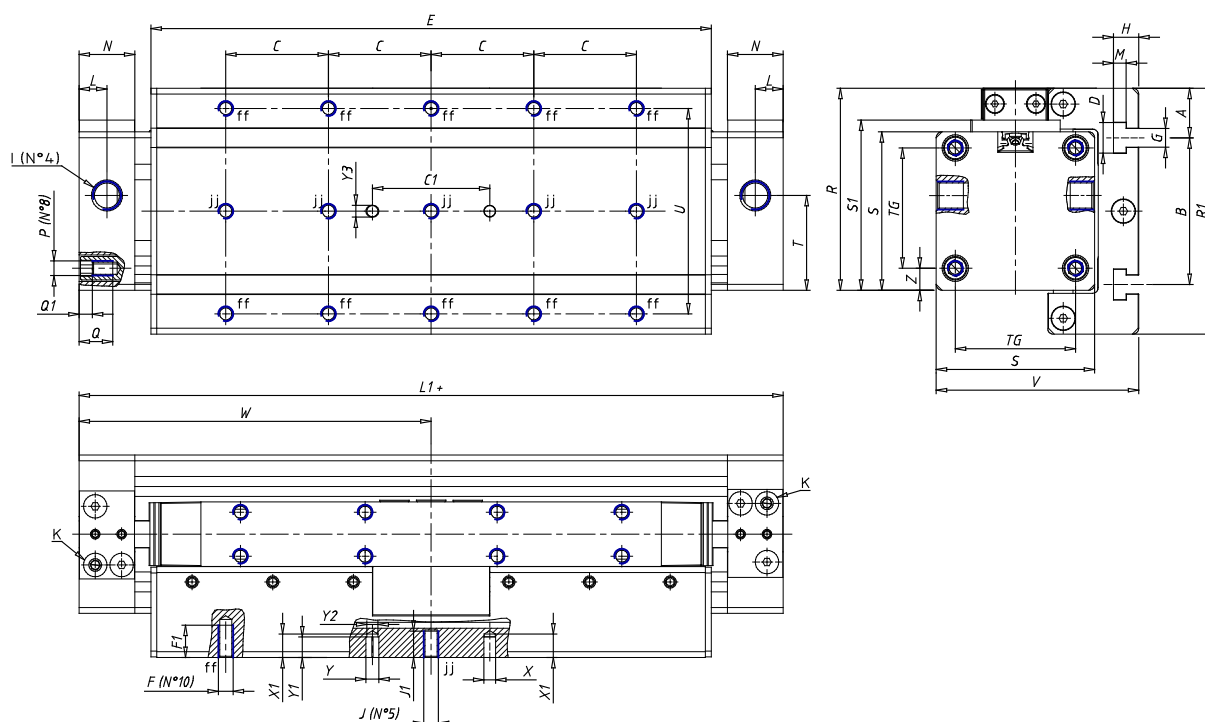

DIMENSIONS

| | |
|----------|-------|
| W (mm) | 175.0 |
| E (mm) | |
| L1 (mm) | 350 |
| I | G3/8 |
| B (mm) | 94 |
| G (mm) | 6.5 |
| N (mm) | 30 |
| L (mm) | 17.0 |
| Ø A (mm) | 23.0 |
| Ø X (mm) | 6.0 |
| S1 (mm) | 94 |
| T (mm) | 59.0 |
| Z (mm) | 12.5 |
| C1 (mm) | 40 |
| C (mm) | 50 |
| U (mm) | 42 |
| F | M8 |
| F1 (mm) | 16.0 |
| H (mm) | 8.5 |
| V (mm) | 112.0 |
| S (mm) | 90 |
| R (mm) | 115 |
| P | M8 |

| | |
|---------|-------|
| TG (mm) | 65 |
| Q (mm) | 17 |
| Q1 (mm) | 5 |
| T1 (mm) | 29.5 |
| T2 (mm) | 59.0 |
| T3 (mm) | 29.0 |
| T4 (mm) | 59.0 |
| L2 (mm) | 17.0 |
| L3 (mm) | 17.0 |
| D (mm) | 10.5 |
| M (mm) | 4.5 |
| J | 0 |
| JP (mm) | 0.0 |
| J1 (mm) | 0 |
| R1 (mm) | 133.0 |
| X1 (mm) | 3.0 |
| Y (mm) | 4.5 |
| Y1 (mm) | 3.0 |
| Y2 (mm) | 0 |
| Y3 (mm) | 6 |
| R2 (mm) | 0.0 |