

Rodless cylinders - Series 52

Product code: 52G8P63A1400

Datasheet creation date: 08/03/2025 14:03

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	52G8P63A
Diameter (mm)	63
Version	G = with slide bearing
Operation	8 = double-acting, cushioned, with air supply from one side only
Materials	P = anodized AL profile tube, NBR and Polyurethane seals, standard carriage
Construction	A = standard
Stroke Cylinder (mm)	1400

Rodless cylinders - Series 52

Product code: 52G8P63A1400

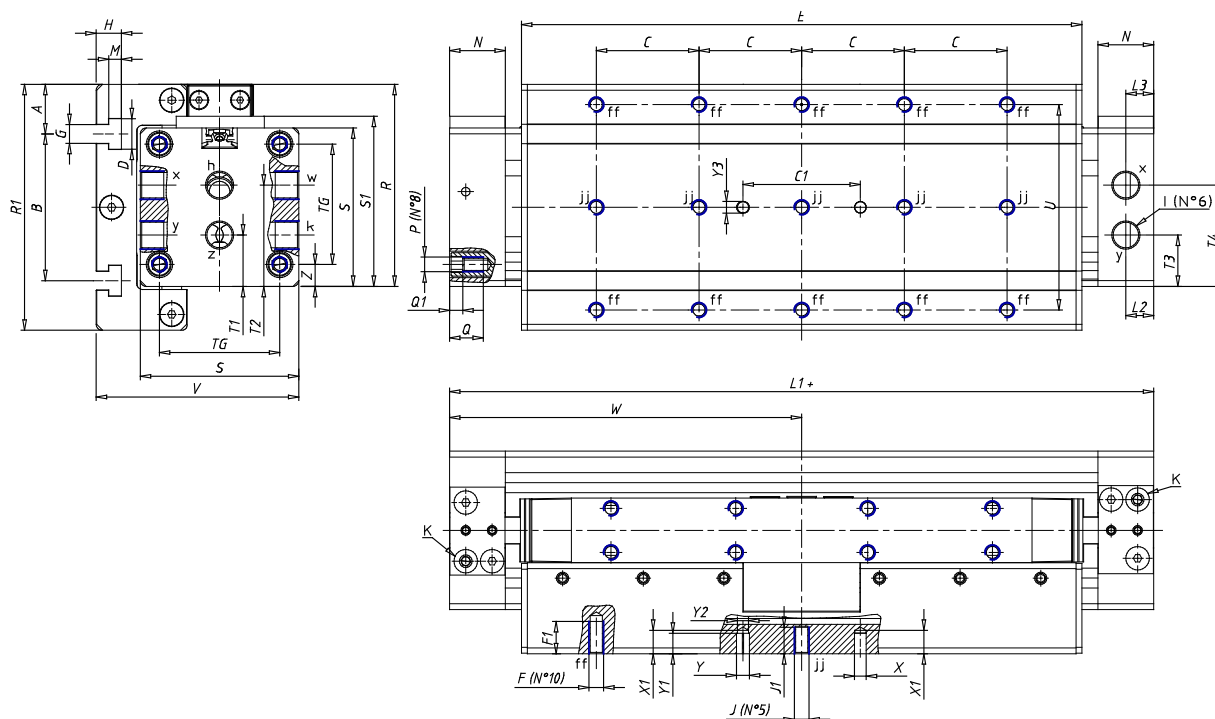

DIMENSIONS

W (mm)	200.0
E (mm)	
L1 (mm)	400
I	G3/8
B (mm)	110
G (mm)	6.5
N (mm)	30
L (mm)	17.0
Ø A (mm)	24.0
Ø X (mm)	6.0
S1 (mm)	110
T (mm)	68.5
Z (mm)	14.0
C1 (mm)	40
C (mm)	60
U (mm)	60
F	M8
F1 (mm)	16.0
H (mm)	8.5
V (mm)	134.5
S (mm)	106
R (mm)	131
P	M8

TG (mm)	78
Q (mm)	17
Q1 (mm)	5
T1 (mm)	34.0
T2 (mm)	68.5
T3 (mm)	34.0
T4 (mm)	68.5
L2 (mm)	17.0
L3 (mm)	17.0
D (mm)	10.5
M (mm)	4.5
J	0
JP (mm)	0.0
J1 (mm)	0
R1 (mm)	150.0
X1 (mm)	6.5
Y (mm)	4.5
Y1 (mm)	6.5
Y2 (mm)	0
Y3 (mm)	6
R2 (mm)	0.0