

## Rodless cylinders - Series 52

Product code: 52M8P50A0650

Datasheet creation date: 08/03/2025 13:26

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	52M8P50A
<b>Diameter (mm)</b>	50
<b>Version</b>	M= standard
<b>Operation</b>	8 = double-acting, cushioned, with air supply from one side only
<b>Materials</b>	P = anodized AL profile tube, NBR and Polyurethane seals, standard carriage
<b>Construction</b>	A = standard
<b>Stroke Cylinder (mm)</b>	650

## Rodless cylinders - Series 52

Product code: 52M8P50A0650

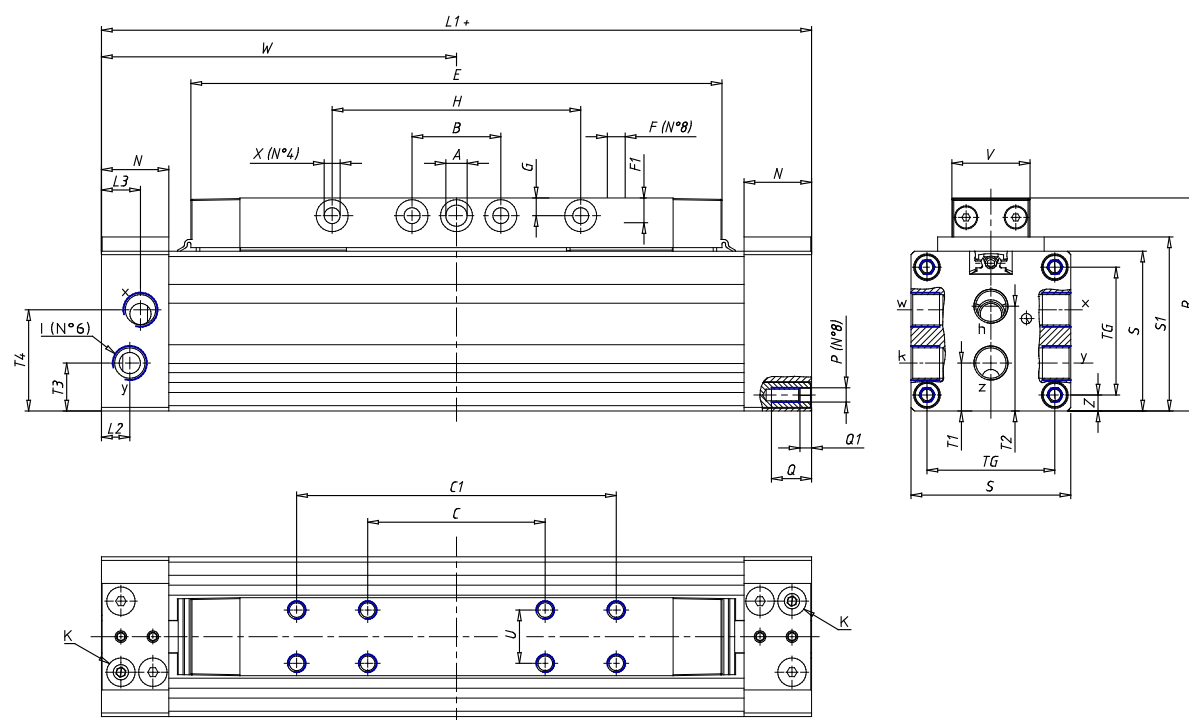

### DIMENSIONS

W (mm)	175.0
E (mm)	262.0
L1 (mm)	350
I	G3/8
B (mm)	35
G (mm)	9.0
N (mm)	30
L (mm)	17.0
$\varnothing A$ (mm)	10.0
$\varnothing X$ (mm)	8.5
S1 (mm)	94
T (mm)	59.0
Z (mm)	12.5
C1 (mm)	150
C (mm)	60
U (mm)	34
F	M8
F1 (mm)	16.0
H (mm)	180.0
V (mm)	46.0
S (mm)	90
R (mm)	115
P	M8

TG (mm)	65
Q (mm)	17
Q1 (mm)	5
T1 (mm)	29.5
T2 (mm)	59.0
T3 (mm)	29.0
T4 (mm)	59.0
L2 (mm)	17.0
L3 (mm)	17.0
D (mm)	10.5
M (mm)	4.5
J	0
JP (mm)	0.0
J1 (mm)	0
R1 (mm)	133.0
X1 (mm)	3.0
Y (mm)	4.5
Y1 (mm)	3.0
Y2 (mm)	0
Y3 (mm)	6
R2 (mm)	0.0