

Vertical electromechanic axis - Series 5V

Product code: 5VS065TBL1500AS1SA

Datasheet creation date: 07/03/2025 16:55

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	5V
Profile	S= square section
Size	065
Transmission	TBL = toothed belt
Stroke (mm)	1500
Version	A= standard
Slider	S= standard
Number of sliders	1= 1 slider
Endcap type	SA = integrated shock absorber

Vertical electromechanic axis - Series 5V

Product code: 5VS065TBL1500AS1SA

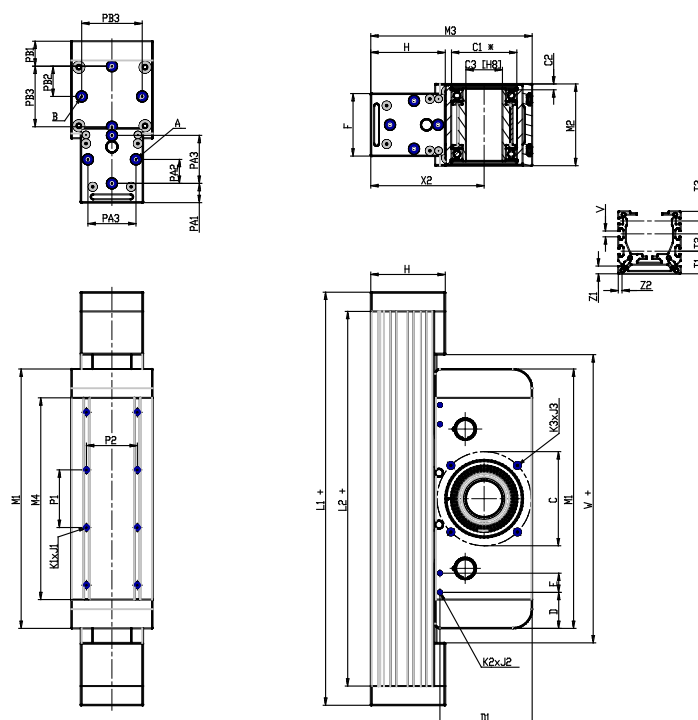

DIMENSIONS

A	M6x9
B	M6x9
C (mm)	98
C1 (mm)	68
C2 (mm)	4.5
C3 (mm)	38
D (mm)	37.5
D1 (mm)	96
E (mm)	20
F (mm)	65
H (mm)	77.5
L1 (mm)	430
L2 (mm)	390
M1 (mm)	270
M2 (mm)	85
M3 (mm)	168
M4 (mm)	210
P1 (mm)	60
P2 (mm)	53
PA1 (mm)	5.0
PA2 (mm)	25.0
PA3 (mm)	50
PB1 (mm)	26

PB2 (mm)	31.5
PB3 (mm)	63
X2 (mm)	118.0
W (mm)	300
K1xJ1	M5x4.7
K2xJ2 (mm)	M3x6
K3xJ3 (mm)	M6x10
Z1 (mm)	8
Z2 (mm)	4
V (mm)	6
T1 (mm)	23.5
T2 (mm)	18
T3 (mm)	10