

Pneumatically and electropneumatically operated valves - Series 8

Product code: 810C3104-F131Y-NPE2CC014-OX2

Datasheet creation date: 10/03/2025 12:02

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	8
Size	10 = Size 1
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	04= G1/8
Orifice diameter	F1= 5.0mm (T1)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	2C = KN 90° type + protection + led - only for size 1
Voltage - power consumption	C014= 24V DC 1.3/0.25
Version	OX2 = for use with oxygen (non volatile residual less than 33 mg/m ²)

Pneumatically and electropneumatically operated valves - Series 8

Product code: 810C3104-F131Y-NPE2CC014-OX2

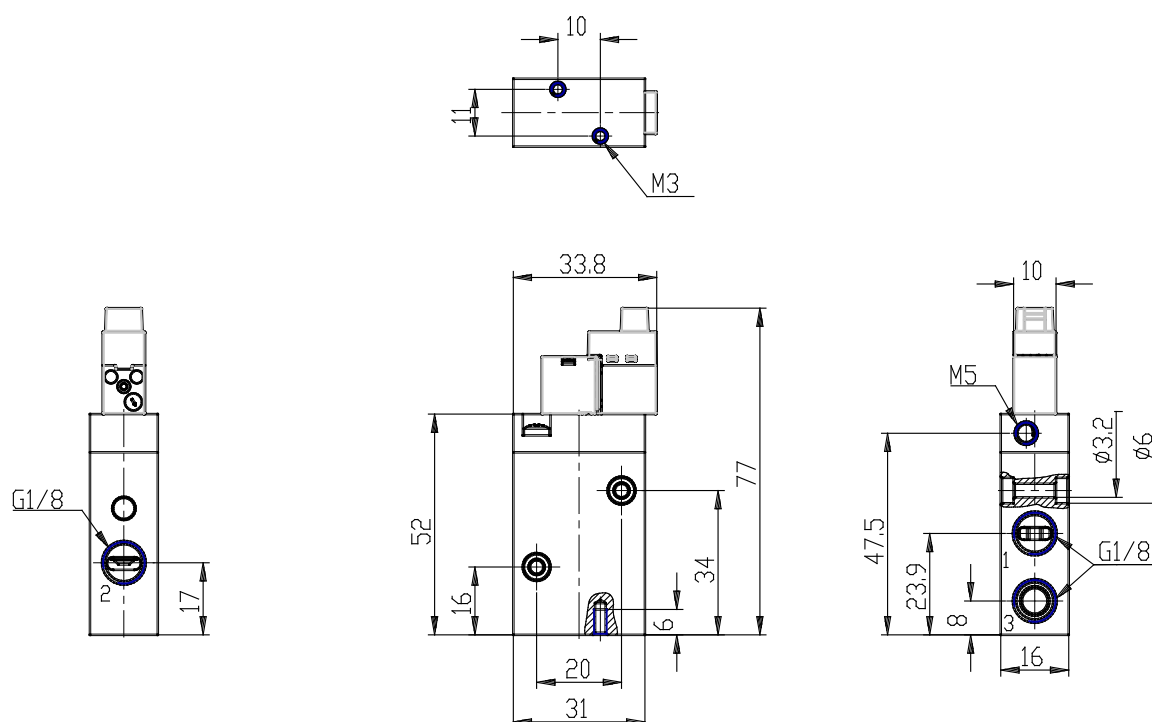

DIMENSIONS

Series	8
Size	10 = Size 1
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	04= G1/8
Orifice diameter	F1= 5.0mm (T1)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	2C = KN 90° type + protection + led - only for size 1
Voltage - power consumption	C014= 24V DC 1.3/0.25
Version	OX2 = for use with oxygen (non volatile residual less than 33 mg/m ²)