

Pneumatically and electropneumatically operated valves - Series 8

Product code: 820C3105-G731Y-NPE4AC023

Datasheet creation date: 10/03/2025 12:03

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	8
Size	20 = Size 2
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	05= G1/4
Orifice diameter	G7= 6.6mm (T2)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	4A = industrial standard (9.4 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	= Standard

Pneumatically and electropneumatically operated valves - Series 8

Product code: 820C3105-G731Y-NPE4AC023

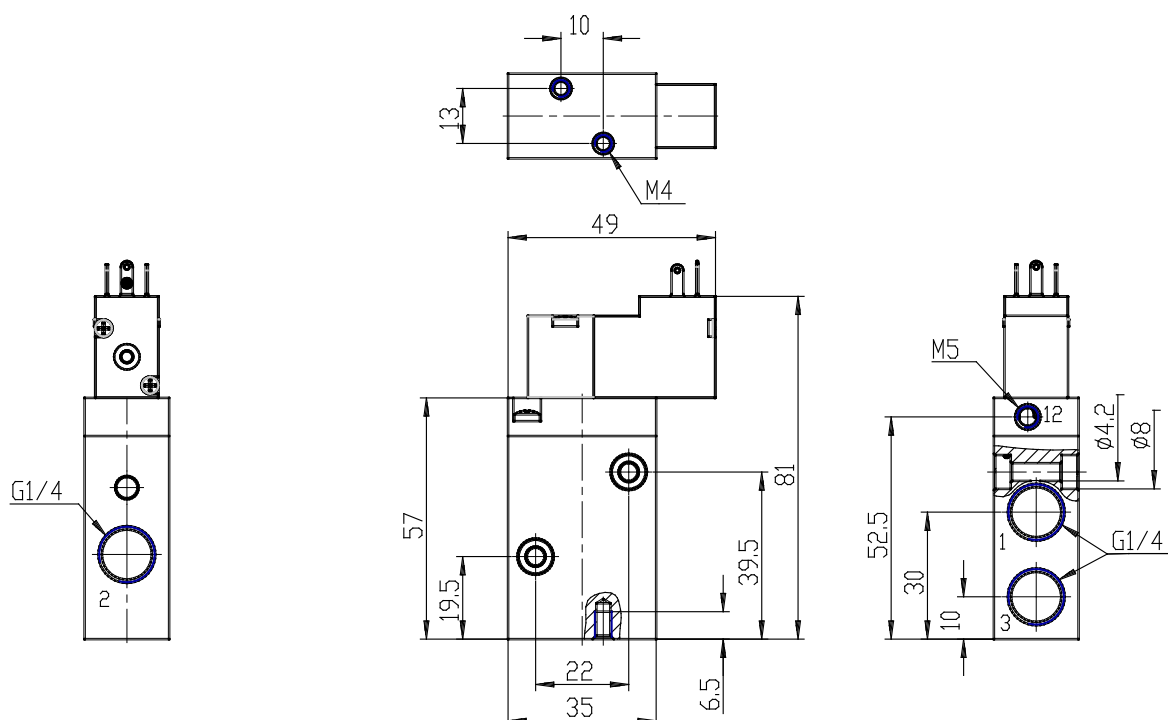

DIMENSIONS

Series	8
Size	20 = Size 2
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	05= G1/4
Orifice diameter	G7= 6.6mm (T2)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	4A = industrial standard (9.4 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	= Standard