

Pneumatically and electropneumatically operated valves - Series 8

Product code: 830C3106-K131Y-NPE4AC023-OX1

Datasheet creation date: 10/03/2025 12:03

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	8
Size	30 = Size 3
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	06= G3/8
Orifice diameter	K1= 9.0mm (T3)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	4A = industrial standard (9.4 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	OX1 = for use with oxygen (non volatile residual less than 550 mg/m ²)

Pneumatically and electropneumatically operated valves - Series 8

Product code: 830C3106-K131Y-NPE4AC023-OX1

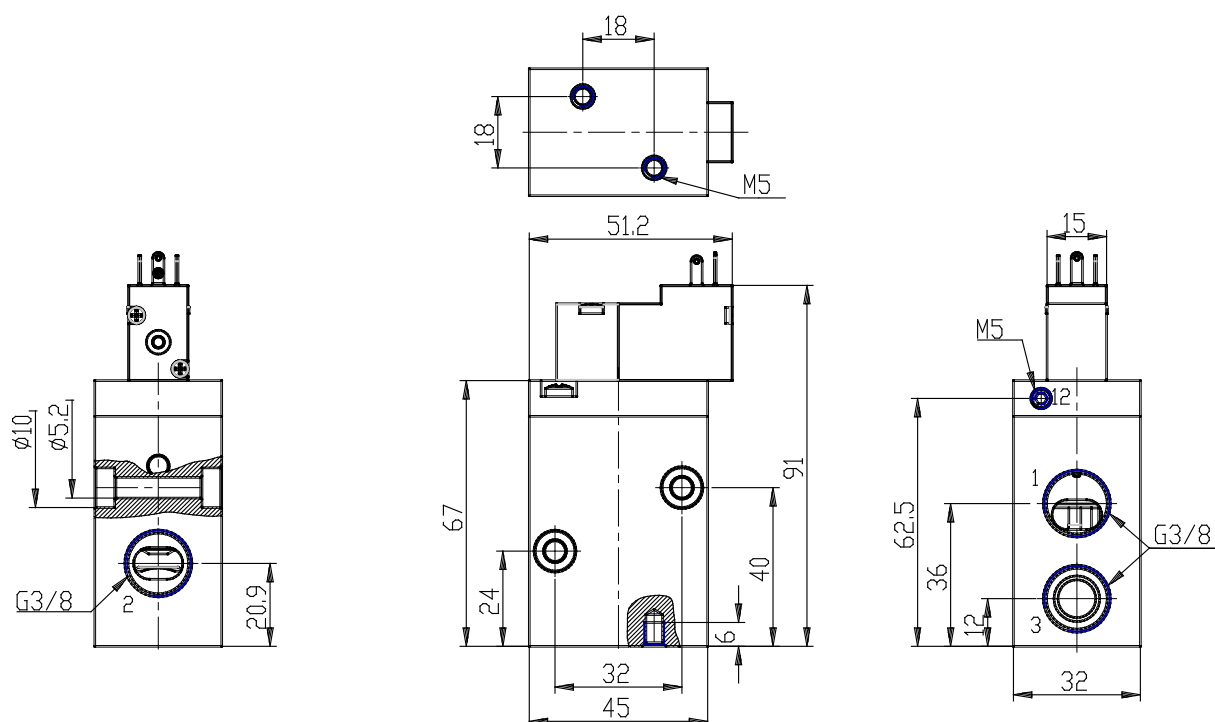

DIMENSIONS

Series	8
Size	30 = Size 3
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	1 = 2/2 NC
Pneumatic connections	06= G3/8
Orifice diameter	K1= 9.0mm (T3)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	4A = industrial standard (9.4 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	OX1 = for use with oxygen (non volatile residual less than 550 mg/m ²)