

Pneumatically and electropneumatically operated valves - Series 8

Product code: 830C3406-K131Y-NPE3AC023

Datasheet creation date: 10/03/2025 12:04

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	8
Size	30 = Size 3
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	4= 3/2 NC
Pneumatic connections	06= G3/8
Orifice diameter	K1= 9.0mm (T3)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	3A = DIN EN 175 301-803-C (8 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	= Standard

Pneumatically and electropneumatically operated valves - Series 8

Product code: 830C3406-K131Y-NPE3AC023

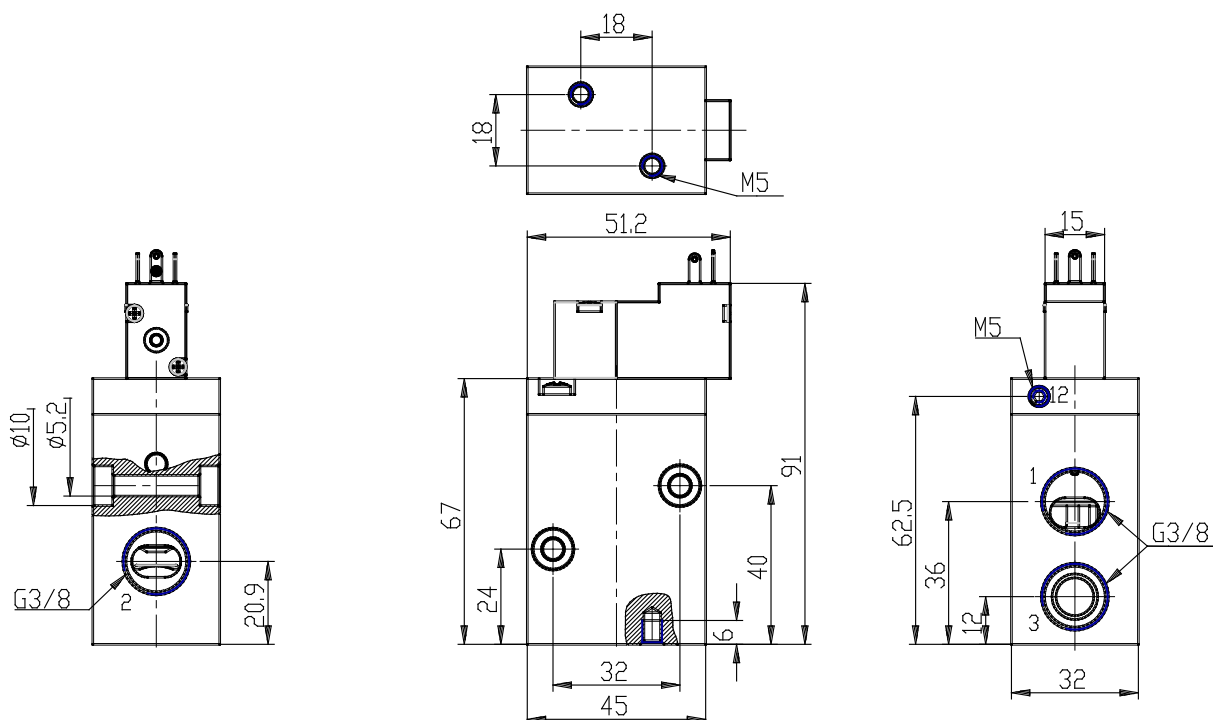

DIMENSIONS

Series	8
Size	30 = Size 3
Body design	C3 = valve with aluminium body threaded connections
Number of ways - Function	4= 3/2 NC
Pneumatic connections	06= G3/8
Orifice diameter	K1= 9.0mm (T3)
Seal material	3 = FKM
Body material	1= aluminium
Manual override	Y = provided monostable
Mounting accessories	N = not provided
Options	PE = electropilot with external piloting
Electrical connection	3A = DIN EN 175 301-803-C (8 mm) - only for size 2 and 3
Voltage - power consumption	C023= 24V DC 2 W
Version	= Standard