

Stainless steel cylinders - Series 97

Product code: 97A2A040A0075V

Datasheet creation date: 20/05/2026 06:39

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	97
Version	A = front end block with pin
Operation	2 = double-acting (front and rear cushioning)
Materials	A = stainless steel AISI 304 - PU seals
Diameter (mm)	40
Construction	A = standard (locking ring for end cap V + lock nut for rod U)
Stroke (mm)	75
Rod length (mm)	0
rod seal in FKM	V = rod seal in FKM

Stainless steel cylinders - Series 97

Product code: 97A2A040A0075V

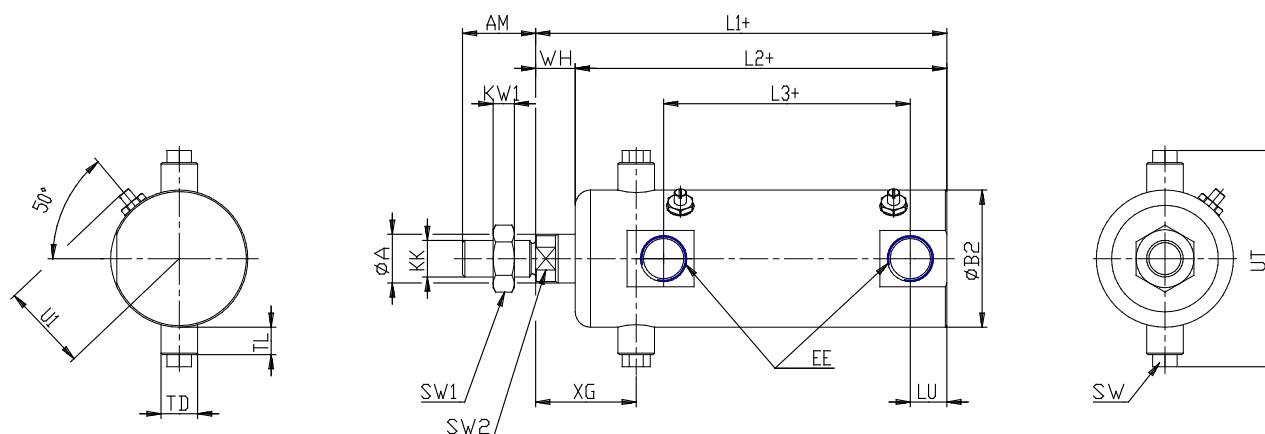

DIMENSIONS

Ø A (mm)	16
AM (mm)	24
Ø B (mm)	-
Ø B2 (mm)	45
CB (mm)	-
CX (mm)	-
EE	G1/4
EP (mm)	-
EX (mm)	-
EW (mm)	-
F (mm)	6
G (mm)	50
KK	M12X1,25
PL (mm)	0.0
SW (mm)	8
SW1 (mm)	19
KW1 (mm)	7
SW2 (mm)	13
U1 (mm)	27
WH (mm)	13.0
L1 (mm)	135.0
L2 (mm)	122.0
L3 (mm)	81

L4 (mm)	-
L7 (mm)	-
L (mm)	-
LT (mm)	-
LU (mm)	12
KW (mm)	-
Ø KV (mm)	-
XD (mm)	-
XG (mm)	33
TD (mm)	12
TL (mm)	9
UB (mm)	-
UT (mm)	71
ZC (mm)	-
Z (mm)	-