

• - **Series 97**

Product code: 97A2V040A0025

Datasheet creation date: 07/03/2025 17:36

Check the most updated document online [click here](#)




**TECHNICAL DATA**

|                             |  |
|-----------------------------|--|
| <b>Series (mm)</b>          | 97   |
| <b>Diameter (mm)</b>        | 40   |
| <b>Version (mm)</b>         | A = front end block with pin                                   |
| <b>Operation (mm)</b>       | 2 = double-acting (front and rear cushions)                    |
| <b>Materials (mm)</b>       | V = stainless steel AISI 304 - FKM seals                       |
| <b>Construction (mm)</b>    | A = standard (locking ring for end cap V + lock nut for rod U) |
| <b>Stroke type</b>          | standard   |
| <b>Stroke (mm)</b>          | 25   |
| <b>rod seal in FKM (mm)</b> | -  |

## • - Series 97

Product code: 97A2V040A0025

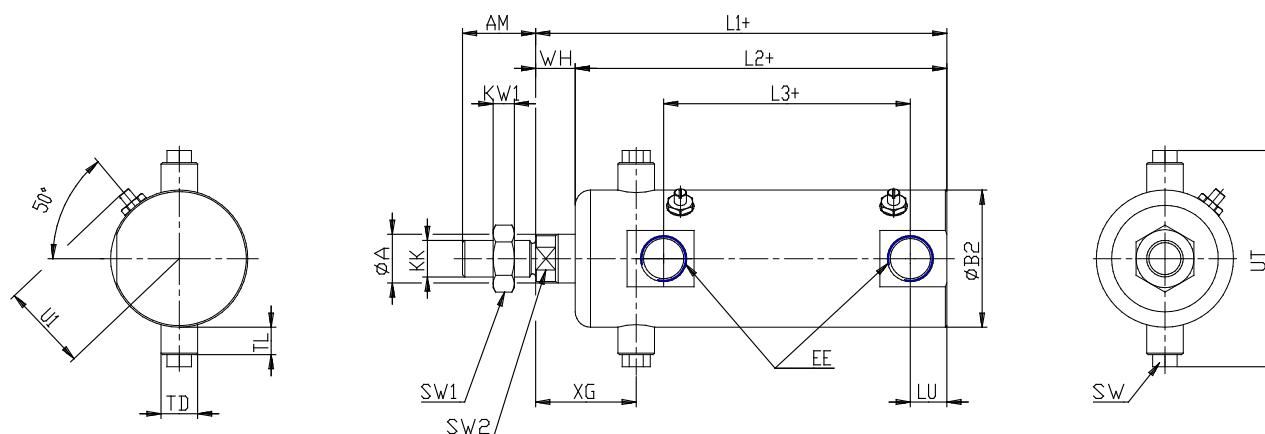

## DIMENSIONS

|           |          |
|-----------|----------|
| Ø A (mm)  | 16       |
| AM (mm)   | 24       |
| Ø B (mm)  | -        |
| Ø B2 (mm) | 45       |
| CB (mm)   | -        |
| CX (mm)   | -        |
| EE (mm)   | G 1/4    |
| EP (mm)   | -        |
| EX (mm)   | -        |
| EW (mm)   | -        |
| F (mm)    | 6        |
| G (mm)    | 50       |
| KK (mm)   | M12X1,25 |
| PL (mm)   | 0.0      |
| SW (mm)   | 8        |
| SW1 (mm)  | 19       |
| KW1 (mm)  | 7        |
| SW2 (mm)  | 13       |
| U1 (mm)   | 27       |
| WH        | 13.0     |
| L1        | 135.0    |
| L2 (mm)   | 122.0    |
| L3 (mm)   | 81       |

|           |    |
|-----------|----|
| L4        | -  |
| L7 (mm)   | -  |
| L (mm)    | -  |
| LT (mm)   | -  |
| LU (mm)   | 12 |
| KW (mm)   | -  |
| Ø KV (mm) | -  |
| XD (mm)   | -  |
| XG (mm)   | 33 |
| TD (mm)   | 12 |
| TL (mm)   | 9  |
| UB (mm)   | -  |
| UT (mm)   | 71 |
| ZC (mm)   | -  |
| Z (mm)    | -  |