

• - Series 97

Product code: 97A2V050A0125

Datasheet creation date: 07/03/2025 17:39

Check the most updated document online [click here](#)




TECHNICAL DATA

Series (mm)	97
Diameter (mm)	50
Version (mm)	A = front end block with pin
Operation (mm)	2 = double-acting (front and rear cushions)
Materials (mm)	V = stainless steel AISI 304 - FKM seals
Construction (mm)	A = standard (locking ring for end cap V + lock nut for rod U)
Stroke type	standard
Stroke (mm)	125
rod seal in FKM (mm)	-

• - Series 97

Product code: 97A2V050A0125

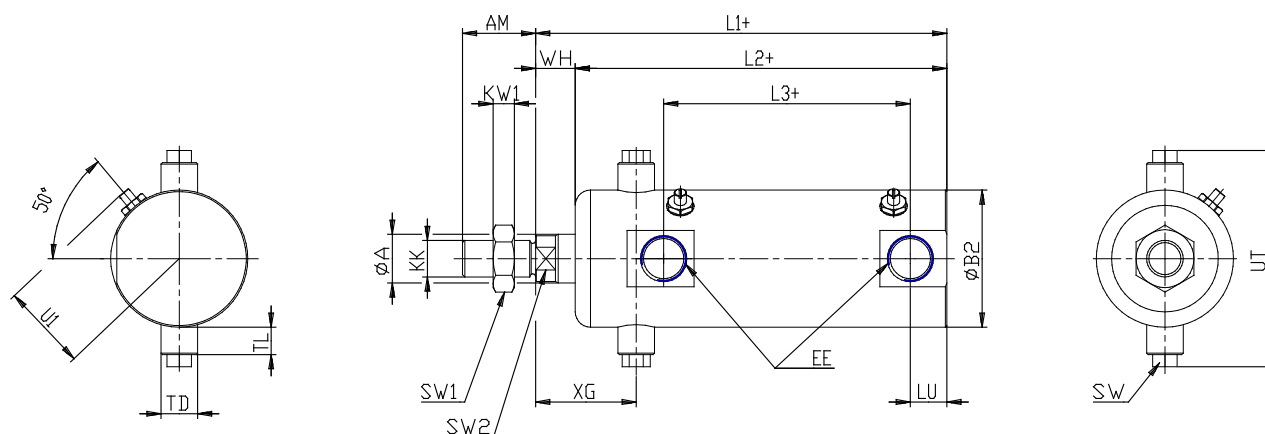

DIMENSIONS

Ø A (mm)	20
AM (mm)	32
Ø B (mm)	-
Ø B2 (mm)	55
CB (mm)	-
CX (mm)	-
EE (mm)	G 1/4
EP (mm)	-
EX (mm)	-
EW (mm)	-
F (mm)	6
G (mm)	53
KK (mm)	M16X1,5
PL (mm)	0.0
SW (mm)	8
SW1 (mm)	24
KW1 (mm)	8
SW2 (mm)	17
U1 (mm)	33
WH	18.0
L1	143.0
L2 (mm)	125.0
L3 (mm)	82

L4	-
L7 (mm)	-
L (mm)	-
LT (mm)	-
LU (mm)	12
KW (mm)	-
Ø KV (mm)	-
XD (mm)	-
XG (mm)	40
TD (mm)	14
TL (mm)	9
UB (mm)	-
UT (mm)	81
ZC (mm)	-
Z (mm)	-