

• - Series 97

Product code: 97T2A032A0025V

Datasheet creation date: 07/03/2025 17:34

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------|--|
| Series (mm) | 97 |
| Diameter (mm) | 32 |
| Version (mm) | T = front and rear threaded end blocks |
| Operation (mm) | 2 = double-acting (front and rear cushions) |
| Materials (mm) | A = stainless steel AISI 304 - PU seals |
| Construction (mm) | A = standard (locking ring for end cap V + lock nut for rod U) |
| Stroke type | standard |
| Stroke (mm) | 25 |
| rod seal in FKM (mm) | V = rod seal in FKM |

• - Series 97

Product code: 97T2A032A0025V

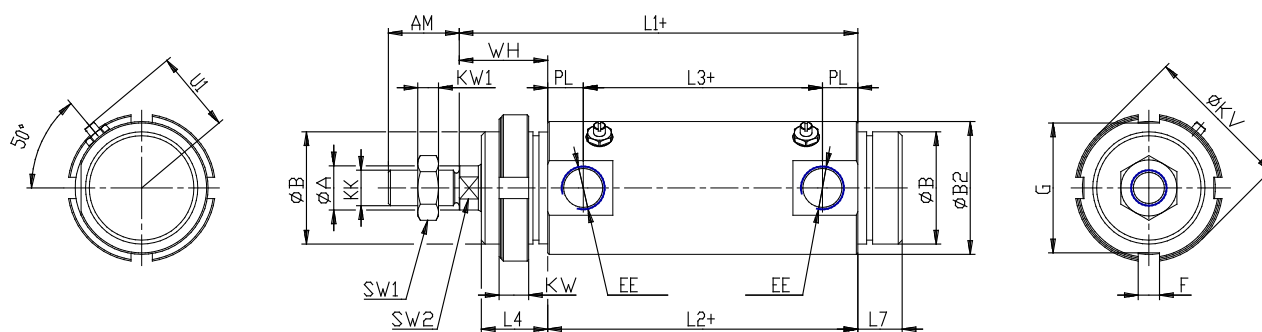

DIMENSIONS

| | |
|-----------|----------|
| Ø A (mm) | 12 |
| AM (mm) | 22 |
| Ø B (mm) | M30X1.5 |
| Ø B2 (mm) | 36 |
| CB (mm) | - |
| CX (mm) | - |
| EE (mm) | G 1/8 |
| EP (mm) | - |
| EX (mm) | - |
| EW (mm) | - |
| F (mm) | 5 |
| G (mm) | 38 |
| KK (mm) | M10X1,25 |
| PL (mm) | 9.0 |
| SW (mm) | - |
| SW1 (mm) | 17 |
| KW1 (mm) | 6 |
| SW2 (mm) | 10 |
| U1 (mm) | 23 |
| WH | 26.0 |
| L1 | 120.0 |
| L2 (mm) | 94.0 |
| L3 (mm) | 76 |

| | |
|-----------|------|
| L4 | 19.5 |
| L7 (mm) | 15 |
| L (mm) | - |
| LT (mm) | - |
| LU (mm) | - |
| KW (mm) | 7 |
| Ø KV (mm) | 42 |
| XD (mm) | - |
| XG (mm) | - |
| TD (mm) | - |
| TL (mm) | - |
| UB (mm) | - |
| UT (mm) | - |
| ZC (mm) | - |
| Z (mm) | - |