

• - **Series 97**

Product code: 97T2A050A0200V

Datasheet creation date: 07/03/2025 17:41

Check the most updated document online [click here](#)




TECHNICAL DATA

Series (mm)	97
Diameter (mm)	50
Version (mm)	T = front and rear threaded end blocks
Operation (mm)	2 = double-acting (front and rear cushions)
Materials (mm)	A = stainless steel AISI 304 - PU seals
Construction (mm)	A = standard (locking ring for end cap V + lock nut for rod U)
Stroke type	standard
Stroke (mm)	200
rod seal in FKM (mm)	V = rod seal in FKM

• - Series 97

Product code: 97T2A050A0200V

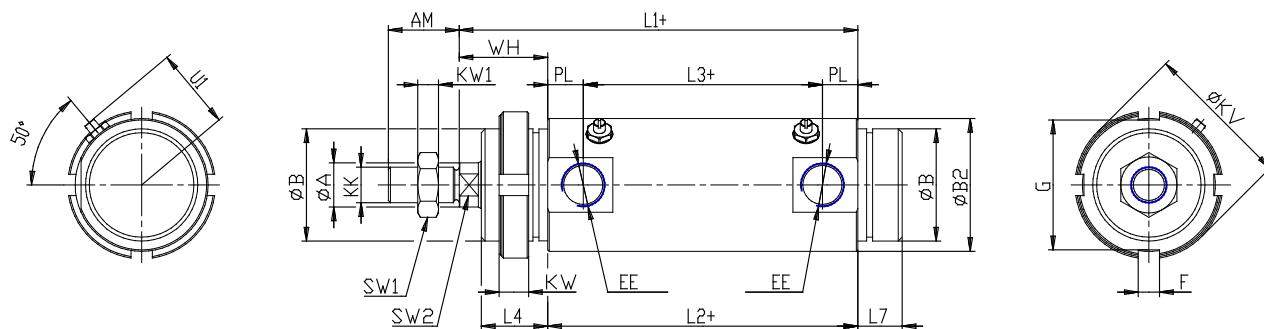

DIMENSIONS

Ø A (mm)	20
AM (mm)	32
Ø B (mm)	M45X1.5
Ø B2 (mm)	55
CB (mm)	-
CX (mm)	-
EE (mm)	G 1/4
EP (mm)	-
EX (mm)	-
EW (mm)	-
F (mm)	6
G (mm)	53
KK (mm)	M16X1,5
PL (mm)	12.0
SW (mm)	-
SW1 (mm)	24
KW1 (mm)	8
SW2 (mm)	17
U1 (mm)	33
WH	37.0
L1	143.0
L2 (mm)	106.0
L3 (mm)	82

L4	28
L7 (mm)	18
L (mm)	-
LT (mm)	-
LU (mm)	-
KW (mm)	10
Ø KV (mm)	60
XD (mm)	-
XG (mm)	-
TD (mm)	-
TL (mm)	-
UB (mm)	-
UT (mm)	-
ZC (mm)	-
Z (mm)	-