

• - Series 97

Product code: 97T2V050A0200

Datasheet creation date: 07/03/2025 17:41

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------|----------------------------------------------------------------|
| Series (mm) | 97 |
| Diameter (mm) | 50 |
| Version (mm) | T = front and rear threaded end blocks |
| Operation (mm) | 2 = double-acting (front and rear cushions) |
| Materials (mm) | V = stainless steel AISI 304 - FKM seals |
| Construction (mm) | A = standard (locking ring for end cap V + lock nut for rod U) |
| Stroke type | standard |
| Stroke (mm) | 200 |
| rod seal in FKM (mm) | - |

• - Series 97

Product code: 97T2V050A0200

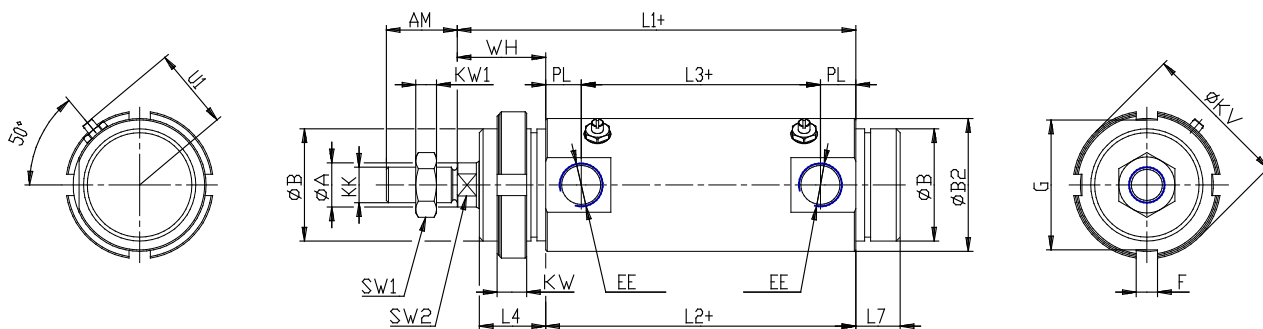

DIMENSIONS

| | |
|-----------|---------|
| Ø A (mm) | 20 |
| AM (mm) | 32 |
| Ø B (mm) | M45X1.5 |
| Ø B2 (mm) | 55 |
| CB (mm) | - |
| CX (mm) | - |
| EE (mm) | G 1/4 |
| EP (mm) | - |
| EX (mm) | - |
| EW (mm) | - |
| F (mm) | 6 |
| G (mm) | 53 |
| KK (mm) | M16X1,5 |
| PL (mm) | 12.0 |
| SW (mm) | - |
| SW1 (mm) | 24 |
| KW1 (mm) | 8 |
| SW2 (mm) | 17 |
| U1 (mm) | 33 |
| WH | 37.0 |
| L1 | 143.0 |
| L2 (mm) | 106.0 |
| L3 (mm) | 82 |

| | |
|-----------|----|
| L4 | 28 |
| L7 (mm) | 18 |
| L (mm) | - |
| LT (mm) | - |
| LU (mm) | - |
| KW (mm) | 10 |
| Ø KV (mm) | 60 |
| XD (mm) | - |
| XG (mm) | - |
| TD (mm) | - |
| TL (mm) | - |
| UB (mm) | - |
| UT (mm) | - |
| ZC (mm) | - |
| Z (mm) | - |