

Rotary cylinders - Series ARP

Product code: ARP-020-1BA-F0710-AEX

Datasheet creation date: 07/03/2025 17:52

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	ARP
Size	020 = torque force 200 Nm
Operation	1B = single-acting, minimum pressure of 5 bar
Rotation angle (°)	A = 90°
Interface for flange (iso 5211)	F0710
Materials	A = standard anodized
Atex	EX

Rotary cylinders - Series ARP

Product code: ARP-020-1BA-F0710-AEX

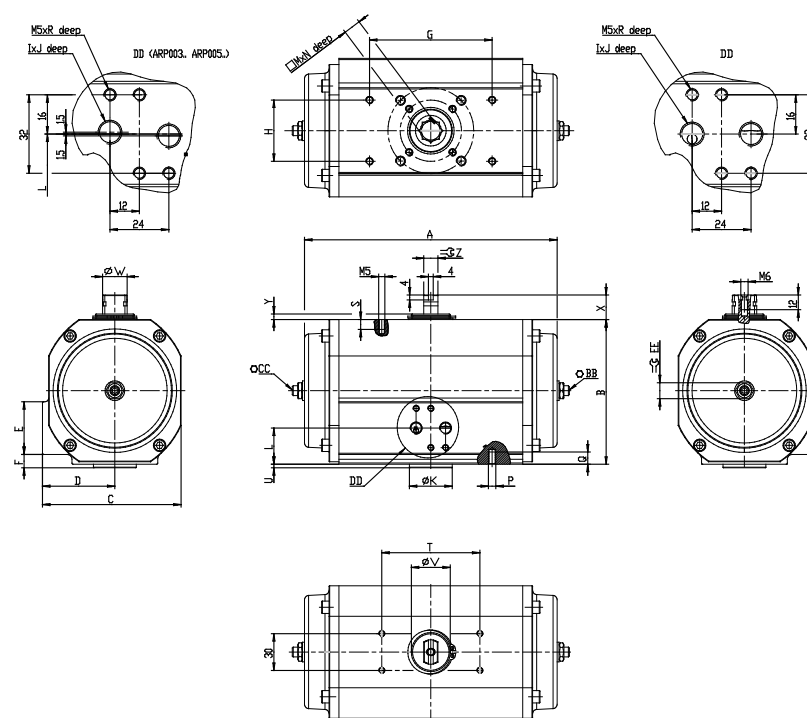

DIMENSIONS

ISO	F07-F10
A (mm)	218.0
B (mm)	140.5
C (mm)	136.5
D (mm)	72.0
E (mm)	43.0
F (mm)	8
G (mm)	107
H (mm)	49
I	G1/4
J (mm)	12
ØK (mm)	55
L (mm)	29.5
M (mm)	17
N (mm)	20
P (mm)	M6
Q (mm)	10
R (mm)	8
S (mm)	5
T (mm)	80
U (mm)	3.0
ØV (mm)	50.0
ØW (mm)	32

X (mm)	20
Y (mm)	6.5
Z (mm)	19.0
BB (mm)	0
CC (mm)	8
EE (mm)	24