


Flange - Mod. DC-63

Product code: DC-63-40

Datasheet creation date: 07/03/2025 16:04

Check the most updated document online [click here](#)

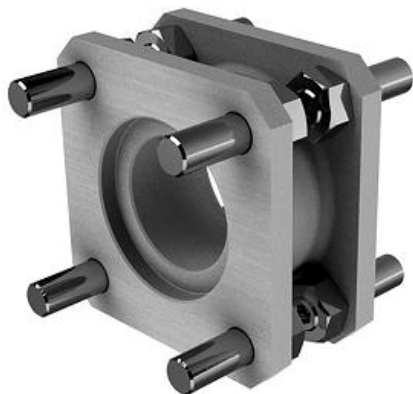


TECHNICAL DATA

Mod.	DC-63-40
------	----------

Flange - Mod. DC-63

Product code: DC-63-40

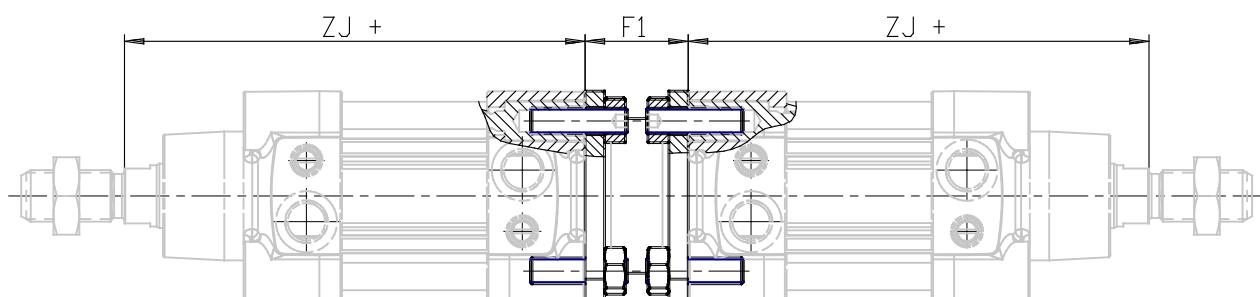

DIMENSIONS

F1 (F1 / mm)	27
ZJ (ZJ / mm)	135
PESO (Weight / g)	160
CORSAMAXTOTALE (Maximum stroke / mm)	800
COPPIASERRAGGIO (Torque force / Nm)	5
A (A / mm)	55
B (B / mm)	38.0
C (C / mm)	35.0
D (Ø D / mm)	6.5
E (E / mm)	5
F (Ø F / mm)	40
G (Ø G / mm)	25
H (Ø H / mm)	35
I (I / mm)	4.5
J (J / mm)	1.5
L (L / mm)	25
M (Ø M / mm)	11.0
N (N / mm)	10
O (O / mm)	5.0