


Flange - Mod. DC-63

Product code: DC-63-50

Datasheet creation date: 07/03/2025 16:04

Check the most updated document online [click here](#)

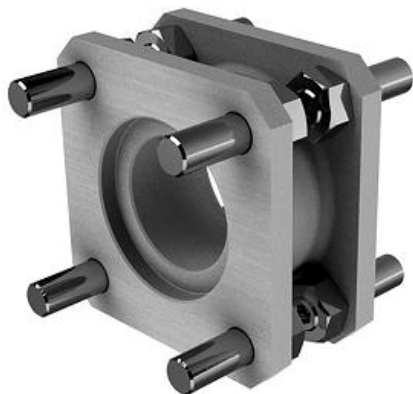


TECHNICAL DATA

| | |
|------|----------|
| Mod. | DC-63-50 |
|------|----------|

Flange - Mod. DC-63

Product code: DC-63-50

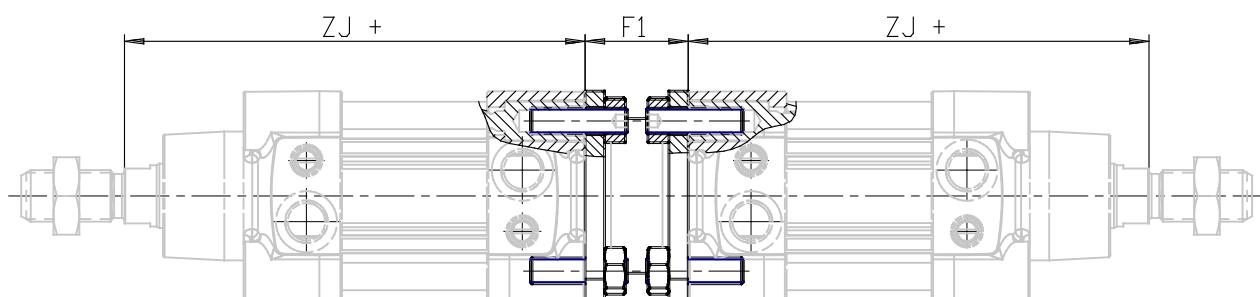

DIMENSIONS

| | |
|--------------------------------------|------|
| F1 (F1 / mm) | 32 |
| ZJ (ZJ / mm) | 143 |
| PESO (Weight / g) | 285 |
| CORSAMAXTOTALE (Maximum stroke / mm) | 800 |
| COPPIASERRAGGIO (Torque force / Nm) | 10 |
| A (A / mm) | 65 |
| B (B / mm) | 46.5 |
| C (C / mm) | 41.5 |
| D (Ø D / mm) | 8.5 |
| E (E / mm) | 6 |
| F (Ø F / mm) | 48 |
| G (Ø G / mm) | 30 |
| H (Ø H / mm) | 40 |
| I (I / mm) | 4.5 |
| J (J / mm) | 2.0 |
| L (L / mm) | 30 |
| M (Ø M / mm) | 15.0 |
| N (N / mm) | 13 |
| O (O / mm) | 6.5 |