

## Direct acting solenoid valves (inline connector) - Series K

Product code: K000-102-FB3M

Datasheet creation date: 10/03/2025 11:30

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	K000
<b>Number of ways - functions</b>	1 = 2/2 vie - NC
<b>Thread port</b>	0 = manifold or single base
<b>Orifice diameter</b>	2 = Ø 0.6 mm - 2/2 version
<b>Materials</b>	F = PBT body - FKM poppet seal
<b>Electrical connection</b>	B = in-line connection with protection and led
<b>Voltage - power consumption</b>	3 = 24 V DC - 1 W
<b>Fixing</b>	M = fixing screws for metal
<b>Options</b>	= standard

## Direct acting solenoid valves (inline connector) - Series K

Product code: K000-102-FB3M

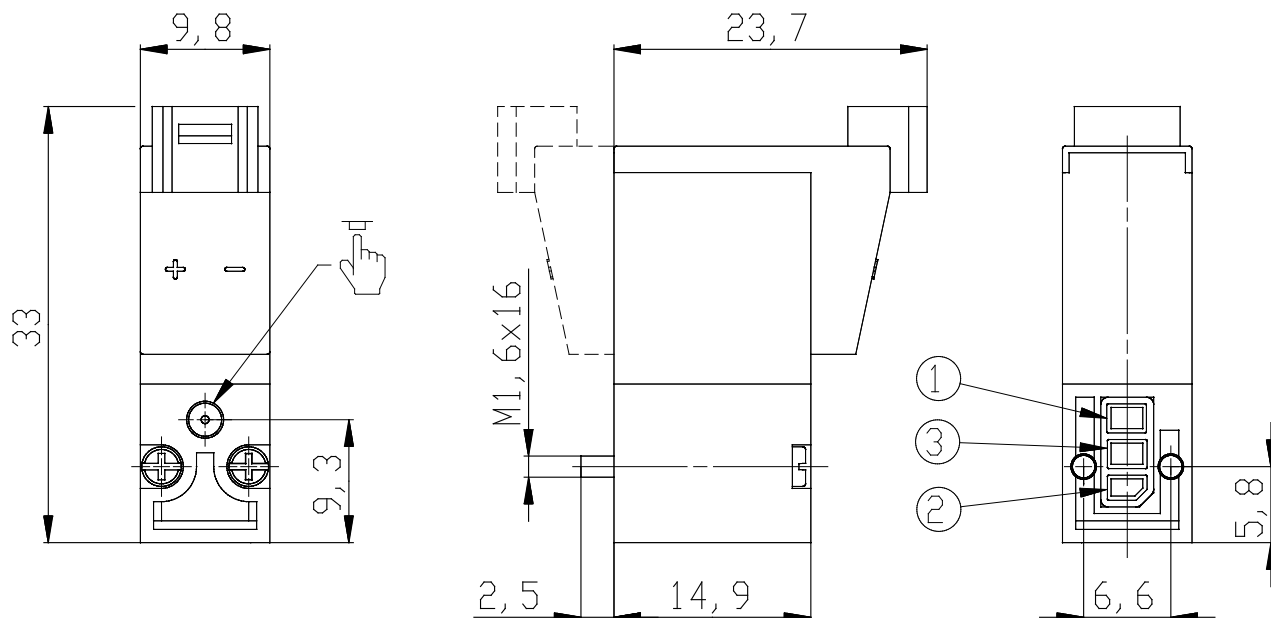

### DIMENSIONS

<b>Series</b>	K000
<b>Number of ways - functions</b>	1 = 2/2 vie - NC
<b>Thread port</b>	0 = manifold or single base
<b>Orifice diameter</b>	2 = Ø 0.6 mm - 2/2 version
<b>Materials</b>	F = PBT body - FKM poppet seal
<b>Electrical connection</b>	B = in-line connection with protection and led
<b>Voltage - power consumption</b>	3 = 24 V DC - 1 W
<b>Fixing</b>	M = fixing screws for metal
<b>Options</b>	= standard