

Media separated solenoid valves - Series KDV

Product code: KDV110-B04G-F7M

Datasheet creation date: 10/03/2025 11:31

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	1 = 2/2-way - NC
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	B0 = Ø 1.0 mm
Seals material	4 = EPDM
Body material	G = PEEK
Electric connection	F = 90° 300 mm flying leads with protection and led
Voltage - power consumption	7 = 12 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna

Media separated solenoid valves - Series KDV

Product code: KDV110-B04G-F7M

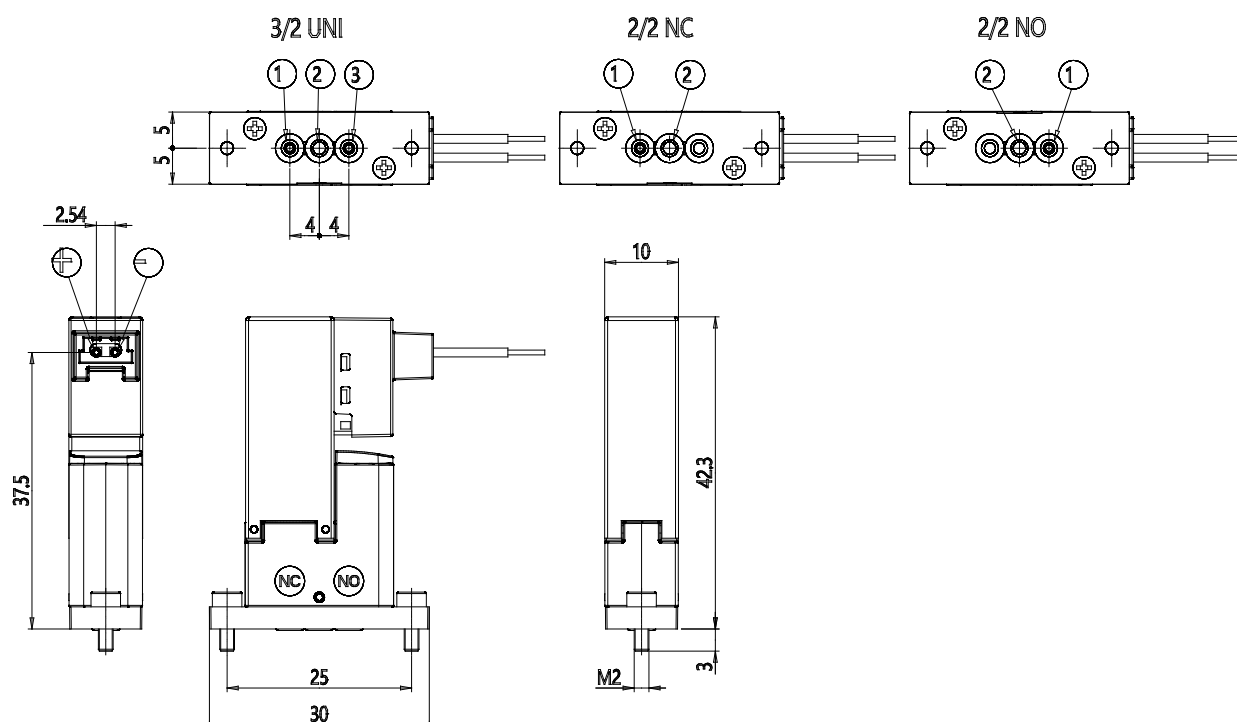

DIMENSIONS

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	1 = 2/2-way - NC
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	B0 = Ø 1.0 mm
Seals material	4 = EPDM
Body material	G = PEEK
Electric connection	F = 90° 300 mm flying leads with protection and led
Voltage - power consumption	7 = 12 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna