

Media separated solenoid valves - Series KDV

Product code: KDV110-B34G-F7M

Datasheet creation date: 10/03/2025 11:31

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|------------------------------------|---|
| Series | KDV |
| Body type - coil position | 1 = flanged body for sub-base |
| Functions | 1 = 2/2-way - NC |
| Pneumatic connection | 0 = su sottobase o manifold |
| Orifice diameter | B3 = Ø 1.3 mm |
| Seals material | 4 = EPDM |
| Body material | G = PEEK |
| Electric connection | F = 90° 300 mm flying leads with protection and led |
| Voltage - power consumption | 7 = 12 VDC - 4/1 W |
| Fixing accessories | M = fixing screws |
| Options | = nessuna |

Media separated solenoid valves - Series KDV

Product code: KDV110-B34G-F7M

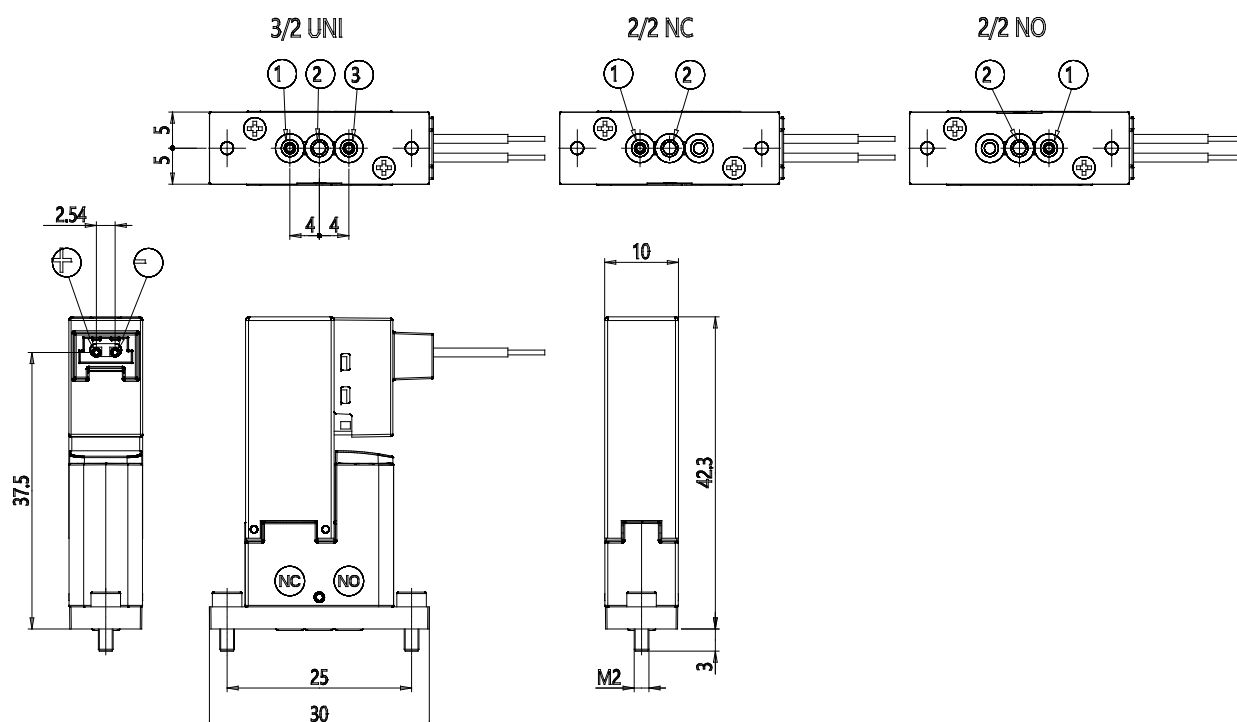

DIMENSIONS

| | |
|------------------------------------|---|
| Series | KDV |
| Body type - coil position | 1 = flanged body for sub-base |
| Functions | 1 = 2/2-way - NC |
| Pneumatic connection | 0 = su sottobase o manifold |
| Orifice diameter | B3 = Ø 1.3 mm |
| Seals material | 4 = EPDM |
| Body material | G = PEEK |
| Electric connection | F = 90° 300 mm flying leads with protection and led |
| Voltage - power consumption | 7 = 12 VDC - 4/1 W |
| Fixing accessories | M = fixing screws |
| Options | = nessuna |