

Media separated solenoid valves - Series KDV

Product code: KDV160-A83G-17M

Datasheet creation date: 10/03/2025 11:31

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	6 = 3/2 way UNI
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	A8 = Ø 0.8 mm
Seals material	3 = FKM
Body material	G = PEEK
Electric connection	1 = 90 ° connector with protection and led
Voltage - power consumption	7 = 12 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna

Media separated solenoid valves - Series KDV

Product code: KDV160-A83G-17M

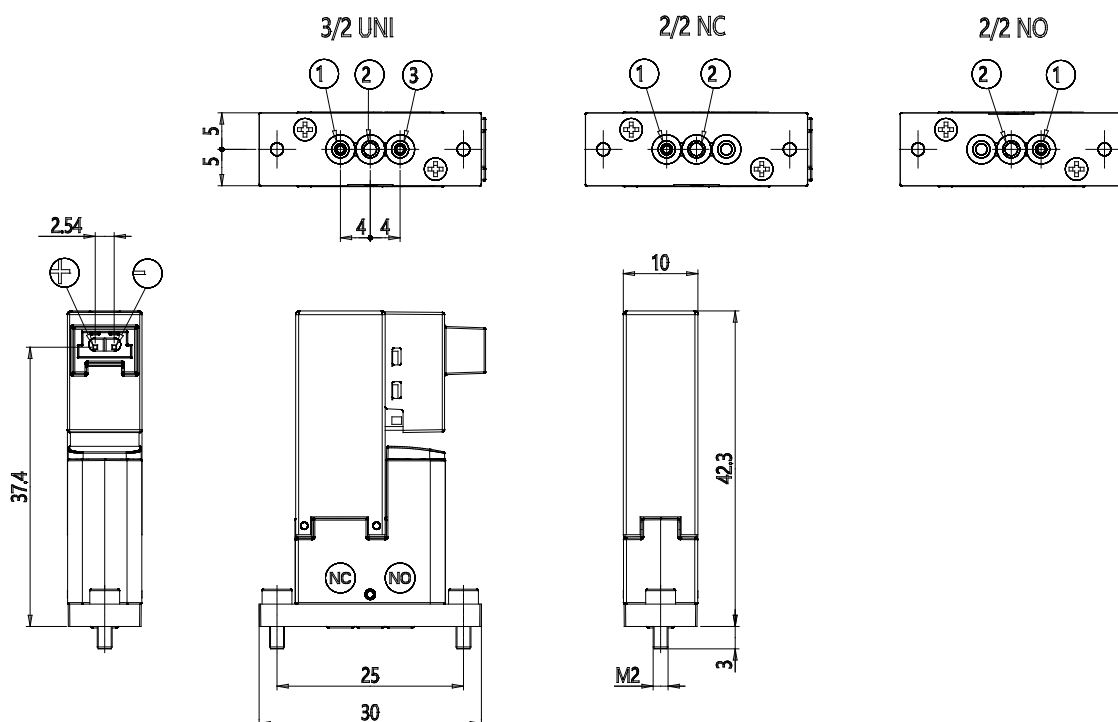

DIMENSIONS

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	6 = 3/2 way UNI
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	A8 = Ø 0.8 mm
Seals material	3 = FKM
Body material	G = PEEK
Electric connection	1 = 90 ° connector with protection and led
Voltage - power consumption	7 = 12 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna