

## Media separated solenoid valves - Series KDV

Product code: KDV160-A84G-F7M

Datasheet creation date: 10/03/2025 11:32

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	KDV
<b>Body type - coil position</b>	1 = flanged body for sub-base
<b>Functions</b>	6 = 3/2 way UNI
<b>Pneumatic connection</b>	0 = su sottobase o manifold
<b>Orifice diameter</b>	A8 = Ø 0.8 mm
<b>Seals material</b>	4 = EPDM
<b>Body material</b>	G = PEEK
<b>Electric connection</b>	F = 90° 300 mm flying leads with protection and led
<b>Voltage - power consumption</b>	7 = 12 VDC - 4/1 W
<b>Fixing accessories</b>	M = fixing screws
<b>Options</b>	= nessuna

## Media separated solenoid valves - Series KDV

Product code: KDV160-A84G-F7M

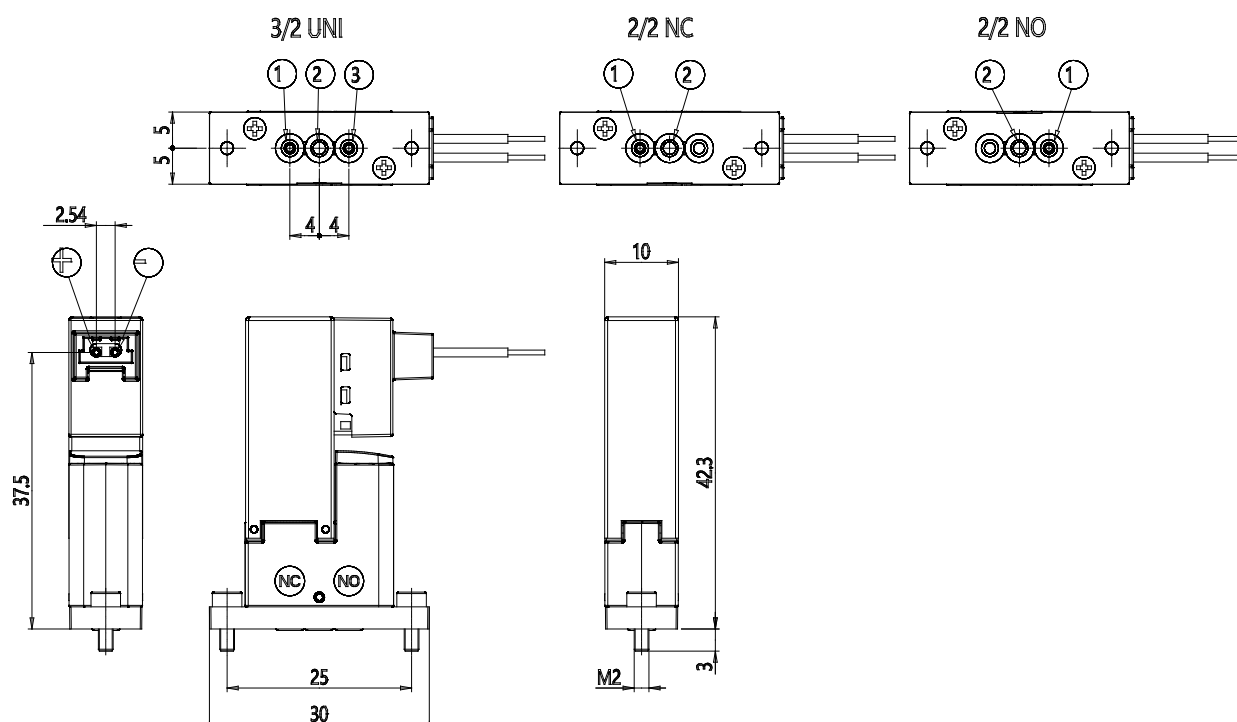

### DIMENSIONS

<b>Series</b>	KDV
<b>Body type - coil position</b>	1 = flanged body for sub-base
<b>Functions</b>	6 = 3/2 way UNI
<b>Pneumatic connection</b>	0 = su sottobase o manifold
<b>Orifice diameter</b>	A8 = Ø 0.8 mm
<b>Seals material</b>	4 = EPDM
<b>Body material</b>	G = PEEK
<b>Electric connection</b>	F = 90° 300 mm flying leads with protection and led
<b>Voltage - power consumption</b>	7 = 12 VDC - 4/1 W
<b>Fixing accessories</b>	M = fixing screws
<b>Options</b>	= nessuna