

Media separated solenoid valves - Series KDV

Product code: KDV160-B34G-F8M

Datasheet creation date: 10/03/2025 11:33

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	6 = 3/2 way UNI
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	B3 = Ø 1.3 mm
Seals material	4 = EPDM
Body material	G = PEEK
Electric connection	F = 90° 300 mm flying leads with protection and led
Voltage - power consumption	8 = 28 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna

Media separated solenoid valves - Series KDV

Product code: KDV160-B34G-F8M

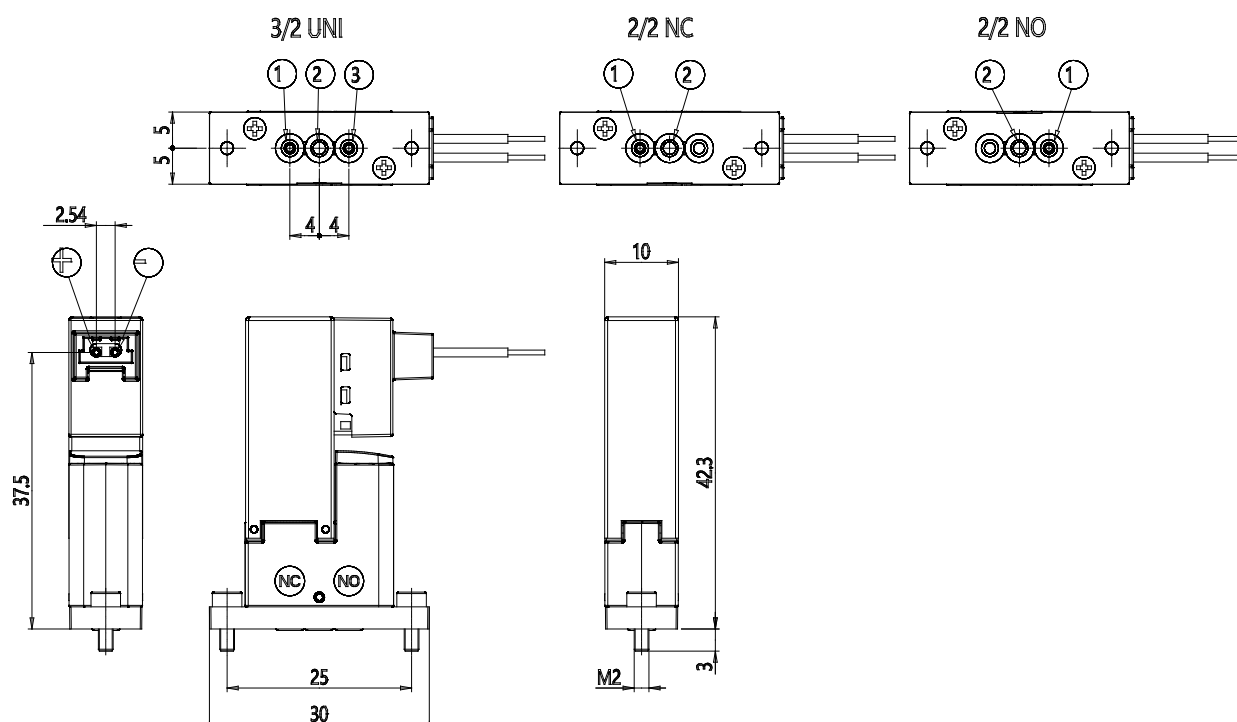

DIMENSIONS

Series	KDV
Body type - coil position	1 = flanged body for sub-base
Functions	6 = 3/2 way UNI
Pneumatic connection	0 = su sottobase o manifold
Orifice diameter	B3 = Ø 1.3 mm
Seals material	4 = EPDM
Body material	G = PEEK
Electric connection	F = 90° 300 mm flying leads with protection and led
Voltage - power consumption	8 = 28 VDC - 4/1 W
Fixing accessories	M = fixing screws
Options	= nessuna