

Direct acting solenoid valves - Series KL

Product code: KL040-A63AY-M3M

Datasheet creation date: 10/03/2025 11:33

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|----------------------------|-----------------------------|
| Series | KL = standard |
| Valvebody | 0 = 3/2 body - ISO 15218 |
| Functions | 4 = 3/2 NC |
| Ports | 0 = on sub-base or manifold |
| Diameter | A6 = Ø0.60 mm |
| Seals material | 3 = FKM |
| Body material | A = PBT |
| Manual Override | Y = monostable |
| Electric connection | M = M8 connector - 3 pins |
| Voltage Power | 3 = 24V DC - 1W |
| Fixing | M = fixing screws for metal |
| Option | = standard |

Direct acting solenoid valves - Series KL

Product code: KL040-A63AY-M3M

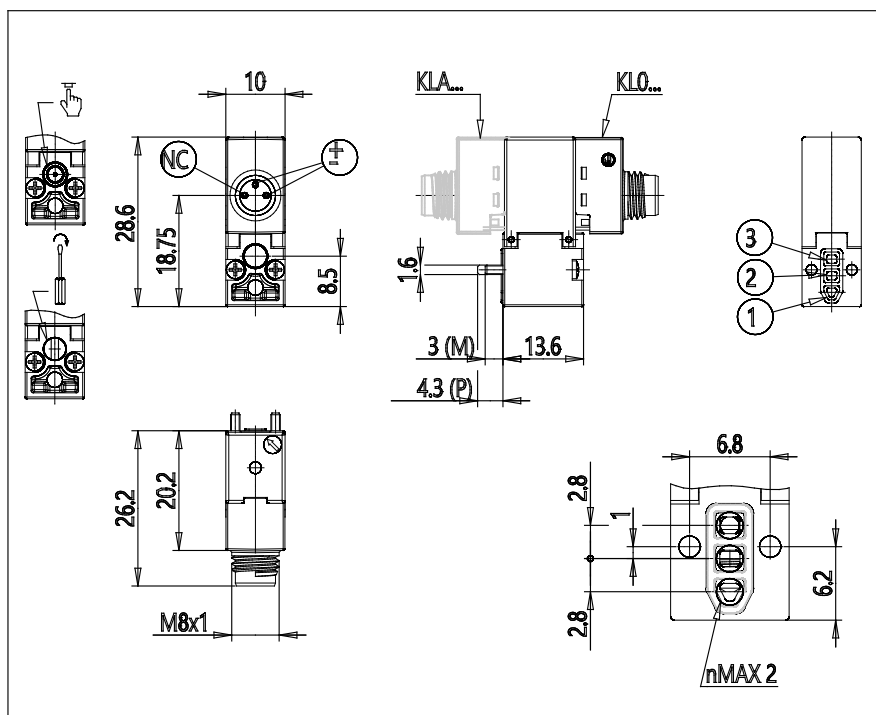

DIMENSIONS

| | |
|----------------------------|-----------------------------|
| Series | KL = standard |
| Valvebody | 0 = 3/2 body - ISO 15218 |
| Functions | 4 = 3/2 NC |
| Ports | 0 = on sub-base or manifold |
| Diameter | A6 = Ø0.60 mm |
| Seals material | 3 = FKM |
| Body material | A = PBT |
| Manual Override | Y = monostable |
| Electric connection | M = M8 connector - 3 pins |
| Voltage Power | 3 = 24V DC - 1W |
| Fixing | M = fixing screws for metal |
| Option | = standard |