

## Direct acting solenoid valve - Series KLE

Product code: KLE040-A83AY-13M

Datasheet creation date: 10/03/2025 11:36

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	KLE = extended
<b>Valvebody</b>	0 = 3/2 body - ISO 15218
<b>Functions</b>	4 = 3/2 NC
<b>Ports</b>	0 = on sub-base or manifold
<b>Diameter</b>	A8 = Ø0.80 mm
<b>Seals material</b>	3 = FKM
<b>Body material</b>	A = PBT
<b>Manual Override</b>	Y = monostable
<b>Electric connection</b>	1 = 90 ° connector with protection and led
<b>Voltage Power</b>	3 = 24V DC - 1W
<b>Fixing</b>	M = fixing screws for metal
<b>Option</b>	= standard

## Direct acting solenoid valve - Series KLE

Product code: KLE040-A83AY-13M

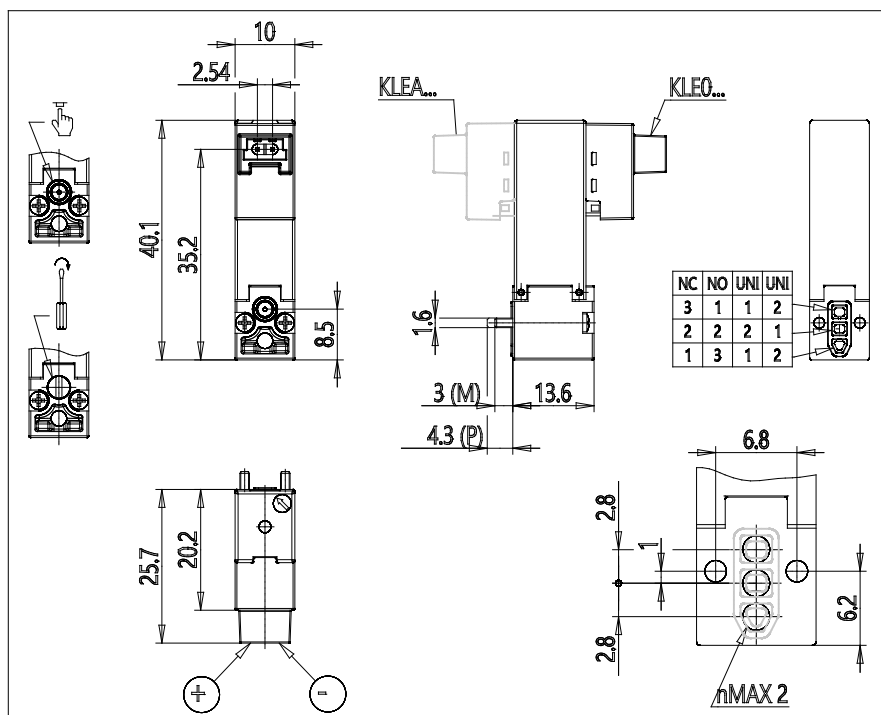

### DIMENSIONS

<b>Series</b>	KLE = extended
<b>Valvebody</b>	0 = 3/2 body - ISO 15218
<b>Functions</b>	4 = 3/2 NC
<b>Ports</b>	0 = on sub-base or manifold
<b>Diameter</b>	A8 = Ø0.80 mm
<b>Seals material</b>	3 = FKM
<b>Body material</b>	A = PBT
<b>Manual Override</b>	Y = monostable
<b>Electric connection</b>	1 = 90 ° connector with protection and led
<b>Voltage Power</b>	3 = 24V DC - 1W
<b>Fixing</b>	M = fixing screws for metal
<b>Option</b>	= standard