

Direct acting solenoid valve - Series KLE

Product code: KLE040-B13AB-B8M

Datasheet creation date: 10/03/2025 11:36

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KLE = extended
Valvebody	0 = 3/2 body - ISO 15218
Functions	4 = 3/2 NC
Ports	0 = on sub-base or manifold
Diameter	B1 = Ø1.10 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	B = bistable
Electric connection	B = in-line connector with protection and led
Voltage Power	8 = 24V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard

Direct acting solenoid valve - Series KLE

Product code: KLE040-B13AB-B8M

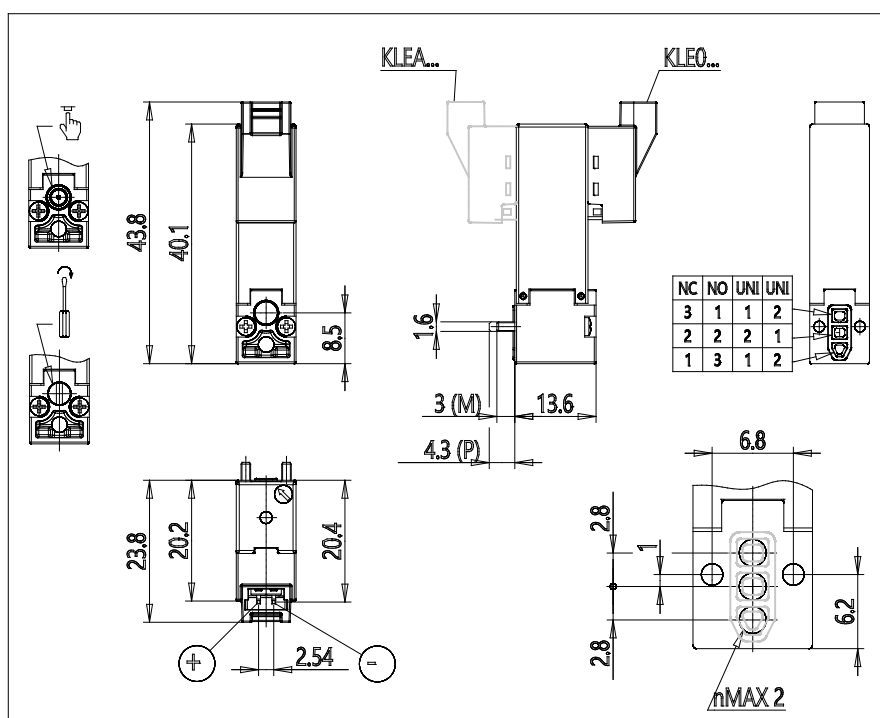

DIMENSIONS

Series	KLE = extended
Valvebody	0 = 3/2 body - ISO 15218
Functions	4 = 3/2 NC
Ports	0 = on sub-base or manifold
Diameter	B1 = Ø1.10 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	B = bistable
Electric connection	B = in-line connector with protection and led
Voltage Power	8 = 24V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard