

Direct acting solenoid valve - Series KLE

Product code: KLE060-A63A0-12M-OX1

Datasheet creation date: 20/05/2026 04:18

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KLE = extended
Valvebody	0 = 3/2 body - ISO 15218
Functions	6 = 3/2 UNI
Ports	0 = on sub-base or manifold
Diameter	A6 = Ø0.60 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	2 = 12V DC - 1W
Fixing	M = fixing screws for metal
Use with oxygen	OX1 = for use with oxygen - cleanliness level according to ASTM G93-03 Standard Level E

Direct acting solenoid valve - Series KLE

Product code: KLE060-A63A0-12M-OX1

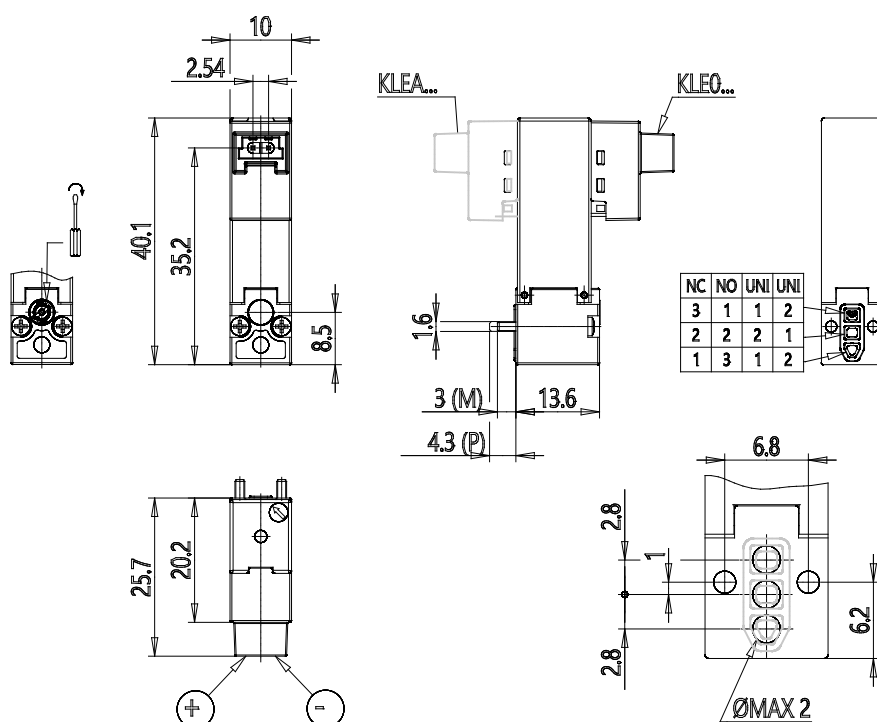

DIMENSIONS

Series	KLE = extended
Valvebody	0 = 3/2 body - ISO 15218
Functions	6 = 3/2 UNI
Ports	0 = on sub-base or manifold
Diameter	A6 = Ø0.60 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	2 = 12V DC - 1W
Fixing	M = fixing screws for metal
Use with oxygen	OX1 = for use with oxygen - cleanliness level according to ASTM G93-03 Standard Level E