

Direct acting solenoid valve - Series KLE

Product code: KLE210-B63A0-B8M

Datasheet creation date: 10/03/2025 11:37

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|----------------------------|---|
| Series | KLE = extended |
| Valvebody | 2 = 2/2 body |
| Functions | 1 =2/2 NC |
| Ports | 0 = on sub-base or manifold |
| Diameter | B6 = Ø1.60 mm |
| Seals material | 3 = FKM |
| Body material | A = PBT |
| Manual Override | 0 = not requested or not foreseen |
| Electric connection | B = in-line connector with protection and led |
| Voltage Power | 8 = 24V DC - 4/1W |
| Fixing | M = fixing screws for metal |
| Option | = standard |

Direct acting solenoid valve - Series KLE

Product code: KLE210-B63A0-B8M

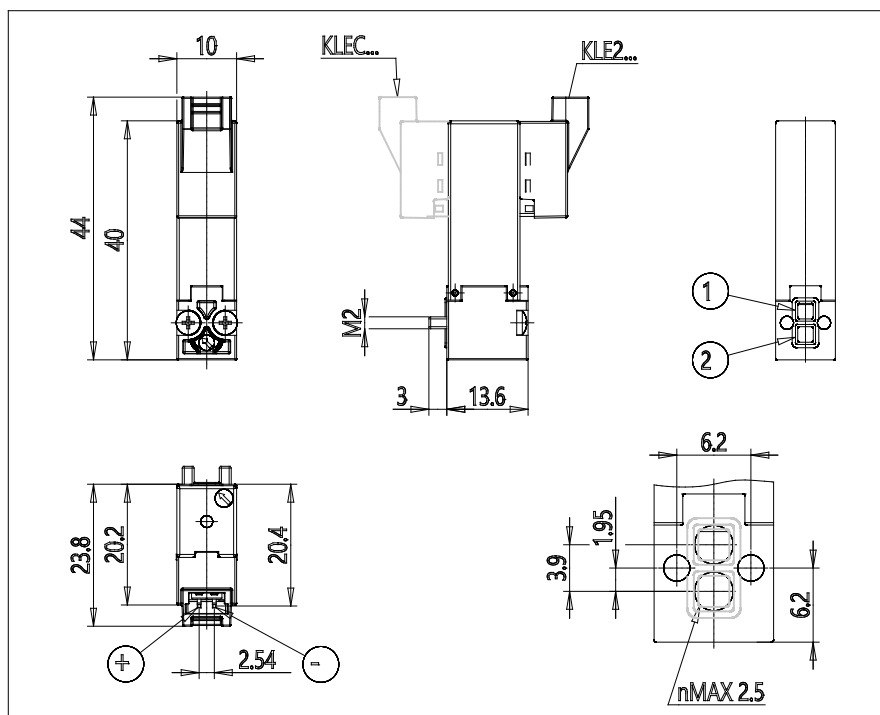

DIMENSIONS

| | |
|----------------------------|---|
| Series | KLE = extended |
| Valvebody | 2 = 2/2 body |
| Functions | 1 = 2/2 NC |
| Ports | 0 = on sub-base or manifold |
| Diameter | B6 = Ø1.60 mm |
| Seals material | 3 = FKM |
| Body material | A = PBT |
| Manual Override | 0 = not requested or not foreseen |
| Electric connection | B = in-line connector with protection and led |
| Voltage Power | 8 = 24V DC - 4/1W |
| Fixing | M = fixing screws for metal |
| Option | = standard |