

Direct acting solenoid valve - Series KLE

Product code: KLEA40-B33A0-16M

Datasheet creation date: 10/03/2025 11:37

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KLE = extended
Valvebody	A = body 3/2 - ISO 15218 - coil rotated by 180 °
Functions	4 = 3/2 NC
Ports	0 = on sub-base or manifold
Diameter	B3 = Ø1.30 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	6 = 6V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard

Direct acting solenoid valve - Series KLE

Product code: KLEA40-B33A0-16M

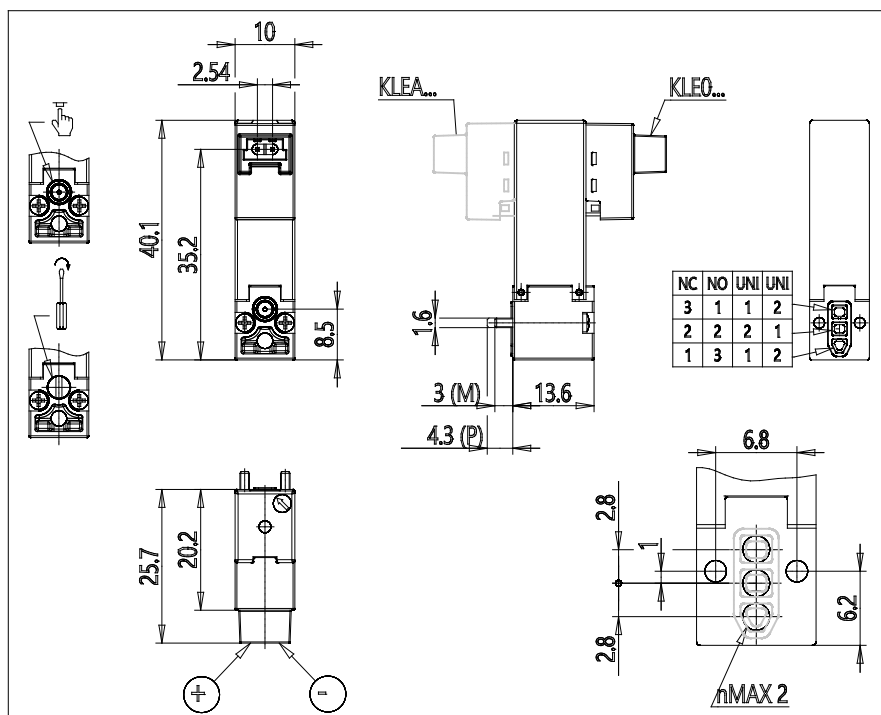

DIMENSIONS

Series	KLE = extended
Valvebody	A = body 3/2 - ISO 15218 - coil rotated by 180 °
Functions	4 = 3/2 NC
Ports	0 = on sub-base or manifold
Diameter	B3 = Ø1.30 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	6 = 6V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard