

Direct acting solenoid valve - Series KLE

Product code: KLEC10-B63A0-18M

Datasheet creation date: 10/03/2025 11:37

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	KLE = extended
Valvebody	C = body 2/2 - coil rotated by 180 °
Functions	1 = 2/2 NC
Ports	0 = on sub-base or manifold
Diameter	B6 = Ø1.60 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	8 = 24V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard

Direct acting solenoid valve - Series KLE

Product code: KLEC10-B63A0-18M

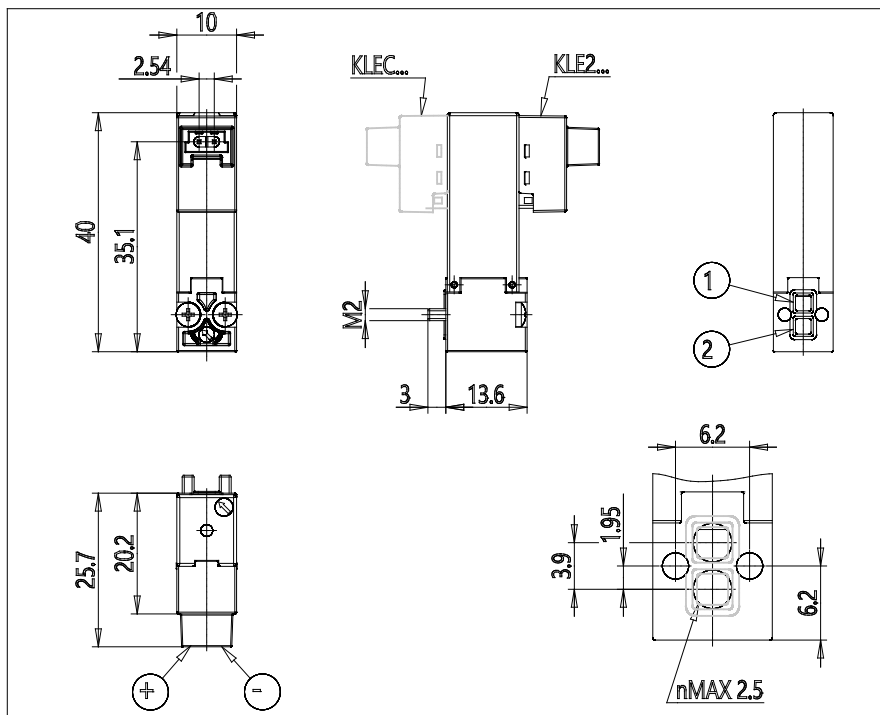

DIMENSIONS

Series	KLE = extended
Valvebody	C = body 2/2 - coil rotated by 180 °
Functions	1 = 2/2 NC
Ports	0 = on sub-base or manifold
Diameter	B6 = Ø1.60 mm
Seals material	3 = FKM
Body material	A = PBT
Manual Override	0 = not requested or not foreseen
Electric connection	1 = 90 ° connector with protection and led
Voltage Power	8 = 24V DC - 4/1W
Fixing	M = fixing screws for metal
Option	= standard