

Direct acting solenoid valves - assembly - Series P

Product code: P104-375-P53

Datasheet creation date: 10/03/2025 11:39

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	P
Body execution	1 = single manifold
Number of seats	4
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	7 = tube Ø 3 mm fittings - bottom outlets
Orifice diameter	5 = Ø 1.1 mm
Materials	P = PBT body - NBR - FKM - PU seals
Electrical connection	5 = industrial standard (9.4 mm)
Voltage - Absorbed power	3 = 24 V DC - 2 W
Fixing	= fixing screws for metal
Options	= Standard

Direct acting solenoid valves - assembly - Series P

Product code: P104-375-P53

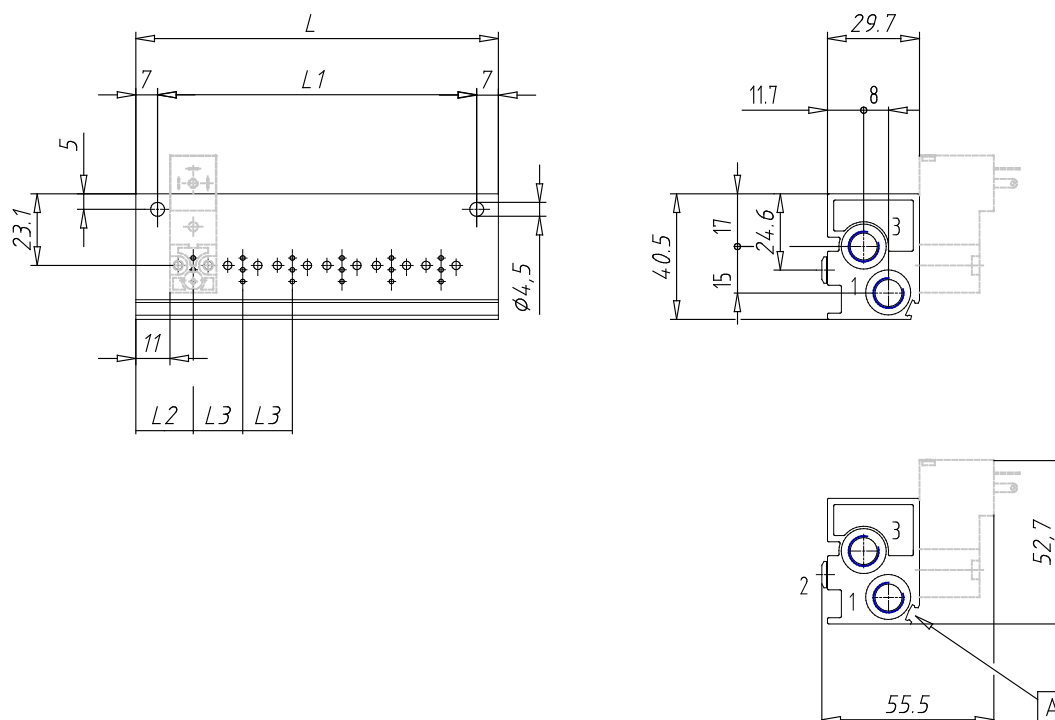

DIMENSIONS

Series	P
Body execution	1 = single manifold
Number of seats	4
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	7 = tube \varnothing 3 mm fittings - bottom outlets
Orifice diameter	5 = \varnothing 1.1 mm
Materials	P = PBT body - NBR - FKM - PU seals
Electrical connection	5 = industrial standard (9.4 mm)
Voltage - Absorbed power	3 = 24 V DC - 2 W
Fixing	= fixing screws for metal
Options	= Standard