

## Direct acting solenoid valves - Series PD

Product code: PD000-2A1-F51

Datasheet creation date: 19/05/2026 16:59

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	PD
<b>Body execution</b>	0 = single body
<b>Number of seats</b>	00 = interface
<b>Number of ways - Functions</b>	2 = 2/2 way - NC
<b>Material - Body connections</b>	A = aluminum body - side interface
<b>Orifice diameter</b>	1 = Ø 0.8 mm
<b>kv (l/min)</b>	0.39
<b>Seal material</b>	F = FKM
<b>Electrical connection</b>	5 = industry standard (9.4 mm)
<b>Voltage - Absorbed power</b>	1 = 12 V DC - 1 W
<b>Fixing</b>	= fixing screws for metal or clips for sub-base
<b>Use with oxygen</b>	= Not suitable for use with oxygen

## Direct acting solenoid valves - Series PD

Product code: PD000-2A1-F51

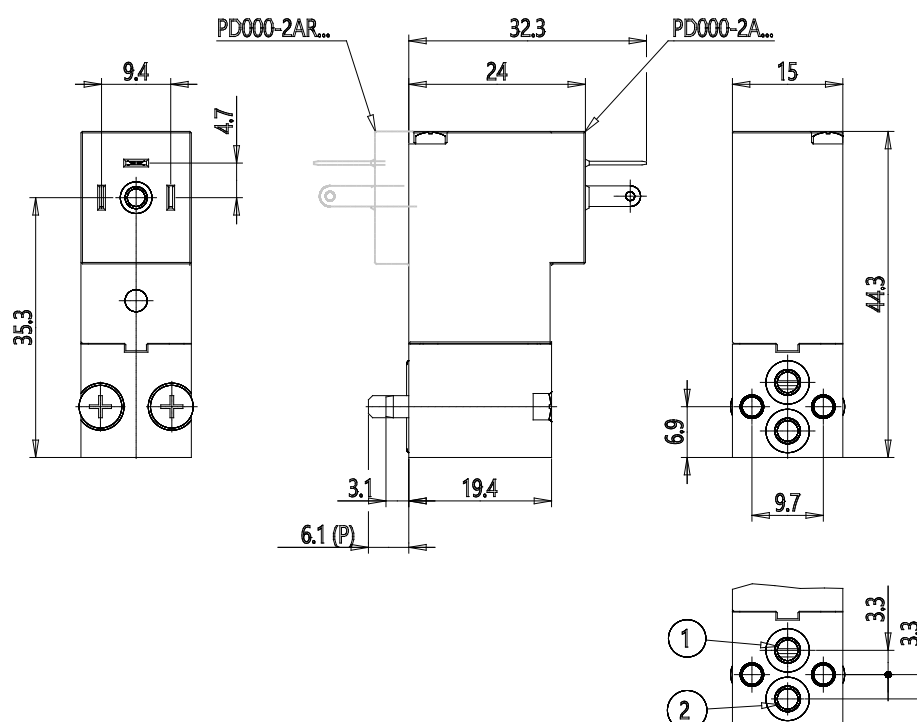

### DIMENSIONS

<b>Series</b>	PD
<b>Body execution</b>	0 = single body
<b>Number of seats</b>	00 = interface
<b>Number of ways - Functions</b>	2 = 2/2 way - NC
<b>Material - Body connections</b>	A = aluminum body - side interface
<b>Orifice diameter</b>	1 = Ø 0.8 mm
<b>kv (l/min)</b>	0.39
<b>Seal material</b>	F = FKM
<b>Electrical connection</b>	5 = industry standard (9.4 mm)
<b>Voltage - Absorbed power</b>	1 = 12 V DC - 1 W
<b>Fixing</b>	= fixing screws for metal or clips for sub-base
<b>Use with oxygen</b>	= Not suitable for use with oxygen