

Direct acting solenoid valves - Series PD

Product code: PD000-2A1-R51

Datasheet creation date: 10/03/2025 11:39

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	1 = Ø 0.8 mm
kv (l/min)	0.39
Seal material	R = NBR
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	1 = 12 V DC - 1 W
Fixing	= fixing screws for metal or clips for sub-base
Options	= Standard

Direct acting solenoid valves - Series PD

Product code: PD000-2A1-R51

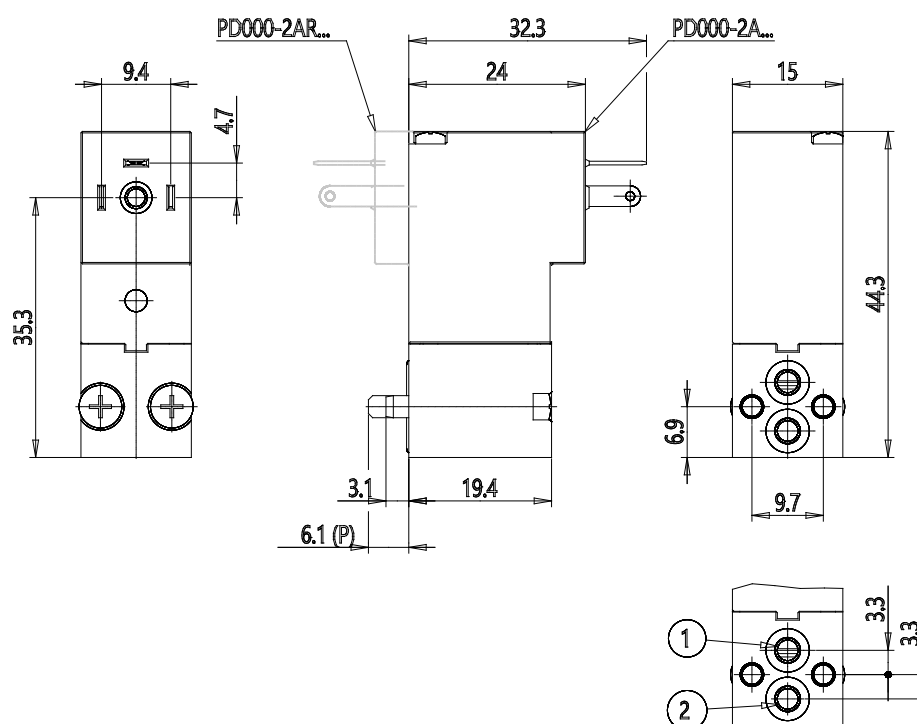

DIMENSIONS

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	1 = Ø 0.8 mm
kv (l/min)	0.39
Seal material	R = NBR
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	1 = 12 V DC - 1 W
Fixing	= fixing screws for metal or clips for sub-base
Options	= Standard